


## Interior separation

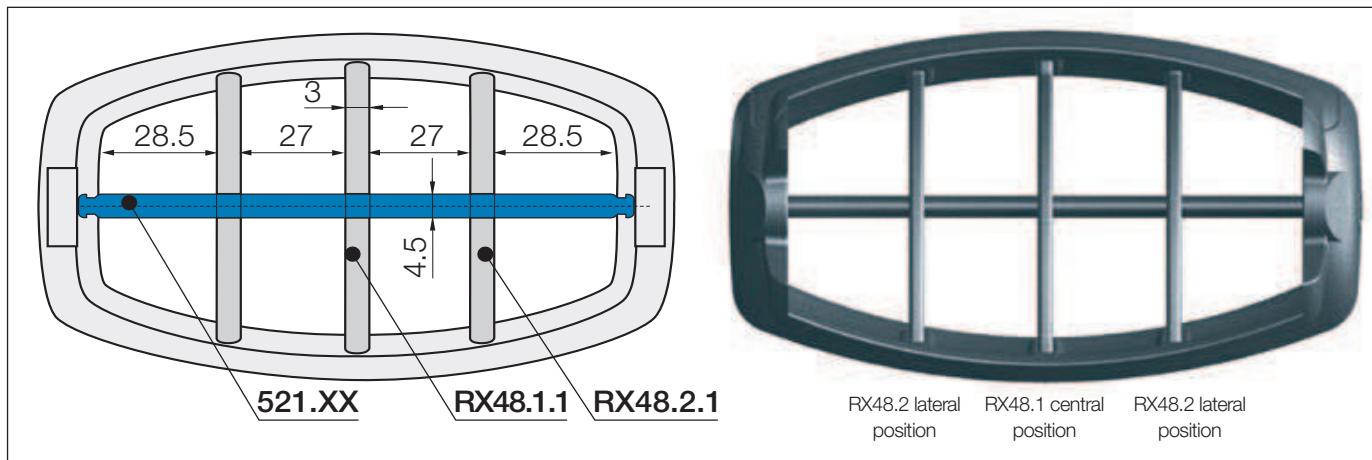

		<b>Slotted separator</b> (central position) unassembled <b>RX48.1</b> assembled <b>RX48.1.1</b>
		<b>Slotted separator</b> (lateral position) unassembled <b>RX48.2</b> assembled <b>RX48.2.1</b>
		<b>Shelf, lockable</b> unassembled <b>520.X</b> assembled <b>521.X</b>

**Vertical separation - slotted separators:****RX48.1** (central position)**RX48.2** (lateral position)

Vertical separation of the large interior space using cable-friendly, polymer separators. Due to their slots, basic vertical and horizontal shelving arrangements are possible. As standard igus® separators should be fitted every 2<sup>nd</sup> e-chain® link.

**Horizontal separation**

Full-width shelf locks securely into separators at both ends, giving a fixed width. Can be used as full-width or partial shelf.



X [mm]	unassembled	assembled	X [mm]	unassembled	assembled
034	<b>520.34</b>	<b>521.34</b>	094	<b>520.94</b>	<b>521.94</b>
064	<b>520.64</b>	<b>521.64</b>	124	<b>520.124</b>	<b>521.124</b>