




Option KMA* - The Standard

- Bolted connection outside of chain cross-section possible
- Split-on KMA mounting bracket
- Corrosion-resistant
- Available with or without strain relief tiwrap plates
- Universal mountable with attachment capability on all sides

*KMA = Polymer Metal Mounting Bracket

Moving end with bore
333...1PZ(B)

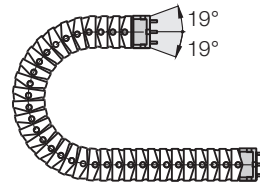


333...2PZ(B)

Fixed end with pin



These fastening variants result automatically on selection of dividable KMA mounting brackets

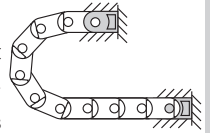


333...1PZ(B)

Moving end

333...2PZ(B)

Fixed end

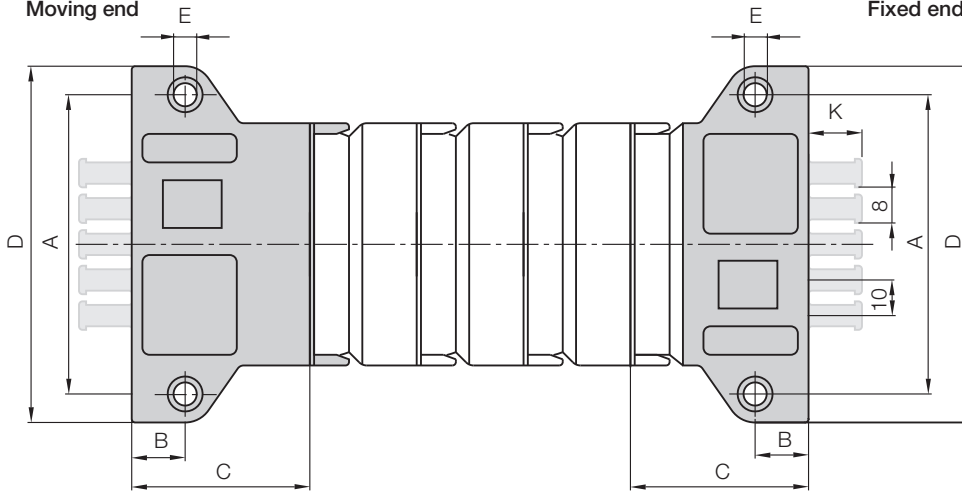

Dimensions and order configurations

For high loads, we recommend screwing the mounting brackets to the E-Chain®. Contact us if you have any questions.

Part No. structure

333.32. 12. PZB A

A... must be indicated on preassembled configurations
With assembled strain relief tiwrap plates

Full set = 12
Mounting brackets for selected chain type

Full set, for both ends:

333. 32. 12 PZB +tiwrap plate

Single-part order:

333. 32. 1 PZB +tiwrap plate

Mounting bracket with bore

333. 32. 2 PZB +tiwrap plate

Mounting bracket with pin

For E-Chain®	Part No. Full set with tiwrap plate	Part No. Full set without tiwrap plate	Dim. A [mm]	Dim. B [mm]	Dim. C [mm]	Dim. D [mm]	Dim. E [mm]	Dim. K [mm]	Dim. Number of teeth
332.32 / 333.32	333.32. 12 PZB	333.32. 12 PZ	66	15	46	82	6,5	15	3
332.50 / 333.50	333.50. 12 PZB	333.50. 12 PZ	84	15	50	100	6,5	15	5
332.75 / 333.75	333.75. 12 PZB	333.75. 12 PZ	109	15	55	125	6,5	15	7
Snap-open series									
352.50 / 353.50	333.50. 12 PZB	333.50. 12 PZ	84	15	50	100	6,5	15	5

For the preassembled mode please add the index A eg. 333.32. 12 PZB A

Tiewrap plate as individual part

Special tiewrap plates for Triflex® E-Chains®

Application: ● Single-piece for installation inside switch cabinets or machine assembly ● Accessory for igus® E-Chain systems® ● Easy to assemble, no need for screws

Part No. Tiewrap plate	Width [mm]	Number of teeth	For Series
333.32.ZB	40	3	332.32 / 333.32
333.50.ZB	58	5	332.50 / 333.50 352.50 / 353.50
333.75.ZB	83	7	332.75 / 333.75

Phone +49- (0) 22 03-96 49-800
Fax +49- (0) 22 03-96 49-222

