





**Option steel - angle**

- One part for all chain widths
- Bolted connection outside of chain cross-section possible
- Electrically conductive
- Galvanized steel
- These elements can be screwed to the floor or roof

Moving end with bore  
338...1

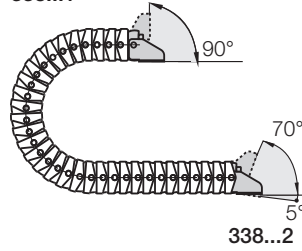

 Fixed end with pin




Possible installation conditions -  
Further installation angles ► installation sketch

338...2  
Fixed end

338...1  
Moving end


**Dimensions and order configurations**

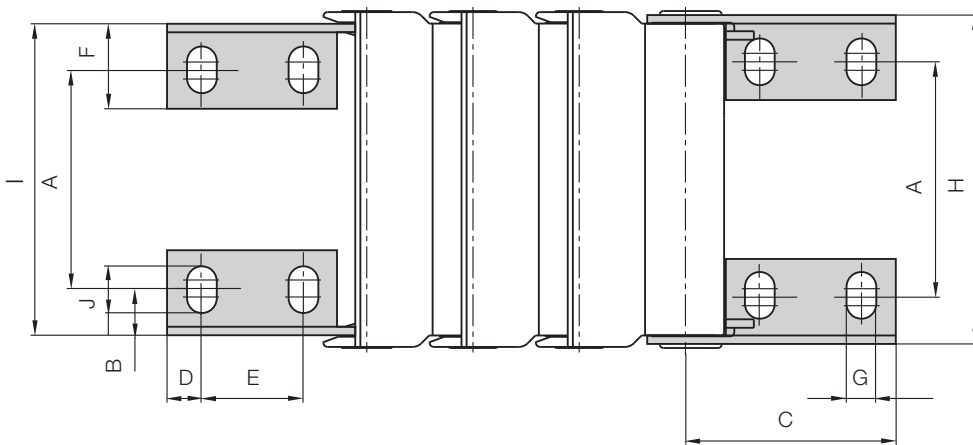

For	Part No.	A	B	C	D	E	F	G	H	I	J
E-Chain®	Full set	[mm]	[mm]	[mm]	[mm]	[mm]	[mm]	[mm]	[mm]	[mm]	[mm]
332.16 / 333.16 ►	338.16. <b>12</b>	12	3	25	5	10	11	4,5	25	23	6
332.32 / 333.32 ►	338.32. <b>12</b>	24	5,5	47	8	24	20	7	49	45	11
332.50 / 333.50 ►	338.50. <b>12</b>	42	5,5	77	12	35	24	9	67	62	15
332.75 / 333.75 ►	338.75. <b>12</b>	65	5,5	77	12	35	24	9	95	90	15
<b>Snap-open Series</b>											
352.50 / 353.50 ►	338.50. <b>12</b>	42	5,5	77	12	35	24	9	67	62	15

Part No. structure

338.	32.	12.
------	-----	-----

 

Full set, 4 parts

2 with pin / 2 with bore:

338.	32.	12
------	-----	----

Single-part order:

338.	32.	1
------	-----	---

Mounting bracket with bore

338.	32.	2
------	-----	---

Mounting bracket with pin

Phone +49- (0) 22 03-96 49-800  
Fax +49- (0) 22 03-96 49-222

