


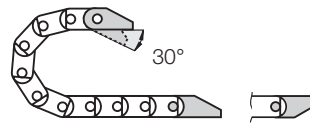


**Polymer, one-piece**

- One-piece mounting bracket
- Corrosion-resistant
- Available preassembled
- Various installation conditions possible

Moving end with bore  
(outer link) 0450...1(PZ)



 0450...2 (PZ) Fixed end  
with pin (inner link)




Possible installation conditions for assembled mounting brackets ► Order example "preassembled" below

0450...1(PZ)  
Moving end

0450...2(PZ)  
Fixed end

**Dimensions and order configurations**

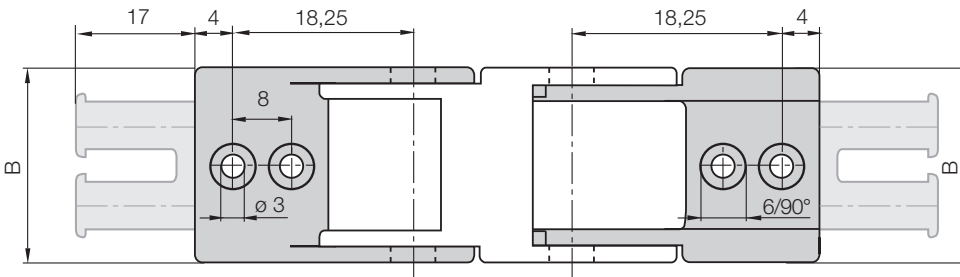

For E-chain®	Part No. full set with tiewrap plate	Part No. full set without tiewrap plate	Number of teeth	Dim. B [mm]
047.10. ►	0450.10. 12 PZ	0450.10. 12	1	16
047.16. ►	0450.16. 12 PZ	0450.16. 12	2	22

**Part No. structure**

0450. 10. 12 PZ A2

A... must be indicated on preassembled configurations with assembled tiewrap plates  
Full set = 12  
Width  
Mounting brackets for selected chain type

Full set, for both ends:

0450. 10. 12

Single-part order:

0450. 10. 1

Mounting bracket with bore

0450. 10. 2

Mounting bracket with pin

For the **preassembled** mode please add the index **A2** and **A4** Example: 0450.10. 12 **A2**



**Quicksnap** - the complete, detachable mounting unit, available upon request



**Quickfix** - mounting bracket with dowel, available upon request

**Additional Features**

