


Part No. structure

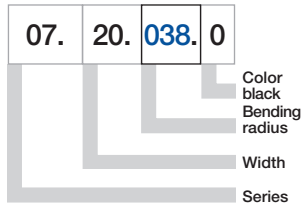

Series 07 E-Chain® - zip-open along outer radius

Part No.	B_i [mm]	B_a [mm]	R [mm]	Bending Radii	Weight [kg/m]
07.06.□.0	06	12,5	018	028 038	≈ 0,13
07.10.□.0	10	16,5	018	028 038	≈ 0,14
07.16.□.0	16	22,5	018	028 038	≈ 0,16
07.20.□.0	20	27	018	028 038	≈ 0,17
07.30.□.0	30	37	018	028 038	≈ 0,20
07.40.□.0	40	47	018	028 038	≈ 0,23
07.50.□.0	50	57	018	028 038	≈ 0,26
07.64.□.0	64	71	018	028 038	≈ 0,30

Supplement part no. with required radius (R) Example: 07.20.□.038.0

0 = standard color, other colors ► page 1.39 · Pitch = 20 mm/link - Links/m = 50



Phone +49- (0) 22 03-96 49-800
Fax +49- (0) 22 03-96 49-222

igus® GmbH
51147 Cologne

Internet: www.igus.eu
E-mail: info@igus.de