




Standard – iglidur® W300 (Standard); sehr verschleißfestes Material

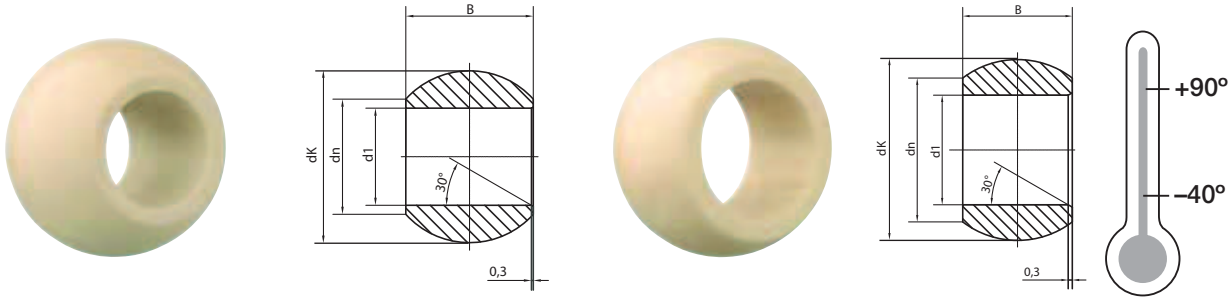

Abmessungen [mm]

igubal®-Kalotten WKM

Bestellnummer	d1 E10	dn	dK	B
WKM-02-04	2,00	3,90	5,10	4,00
WKM-03-06	3,00	5,10	8,10	6,00
WKM-05-08	5,00	7,70	11,30	8,00
WKM-06-09	6,00	8,90	12,80	9,00
WKM-08-12	8,00	10,30	16,00	12,00
WKM-10-14	10,00	12,90	19,00	14,00
WKM-12-16	12,00	15,40	22,10	16,00
WKM-14-19	14,00	16,80	25,40	19,00
WKM-16-21	16,00	19,30	28,40	21,00
WKM-18-23	18,00	21,80	31,50	23,00
WKM-20-25	20,00	24,30	35,10	25,00
WKM-22-28	22,00	25,80	38,30	28,00
WKM-25-31	25,00	29,50	42,90	31,00
WKM-30-37	30,00	34,80	51,20	37,00

Abmessungen [mm]

igubal®-Kalotten WEM

Bestellnummer	d1 E10	dn	dK	B
WEM-04-05	4,00	6,25	8,30	5,00
WEM-05-06	5,00	8,00	10,30	6,00
WEM-06-06	6,00	8,00	10,30	6,00
WEM-08-08	8,00	10,00	13,30	8,00
WEM-10-09	10,00	13,00	16,20	9,00
WEM-12-10	12,00	15,00	18,10	10,00
WEM-15-12	15,00	18,00	22,00	12,00
WEM-16-13	16,00	19,50	24,10	13,00
WEM-17-14	17,00	20,00	25,10	14,00
WEM-20-16	20,00	24,00	29,10	16,00
WEM-25-20	25,00	29,00	35,60	20,00
WEM-30-22	30,00	34,00	40,90	22,00

Abmessungen [Inch]

igubal®-Kalotten WKI

Bestellnummer	d1 E10	dn	dK	B
WKI-03	,1900	,307	,444	,312
WKI-04	,2500	,354	,523	,375
WKI-05	,3125	,447	,633	,437
WKI-06	,3750	,504	,720	,500
WKI-07	,4375	,601	,830	,562
WKI-08	,5000	,700	,937	,625
WKI-10	,6250	,838	1,130	,750
WKI-12	,7500	,978	1,311	,875
WKI-16	1,0000	1,269	1,756	1,375

Abmessungen [Inch]

igubal®-Kalotten WEI

Bestellnummer	d1 H10	dn	dK	B
WEI-03	,1900	,354	,402	,1900
WEI-04	,2500	,314	,398	,2500
WEI-05	,3125	,415	,519	,3125
WEI-06	,3750	,506	,626	,3750
WEI-07	,4375	,581	,709	,4063
WEI-08	,5000	,581	,713	,4063
WEI-10	,6250	,802	,945	,5000
WEI-12	,7500	,951	1,138	,6250
WEI-16	1,0000	1,180	1,398	,7500

igubal®-Kugelkalotten
mm/Inch W...M/I

Telefon (0 22 03) 96 49-145
Telefax (0 22 03) 96 49-334

