
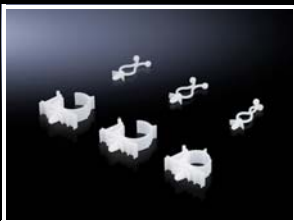


# Cable management

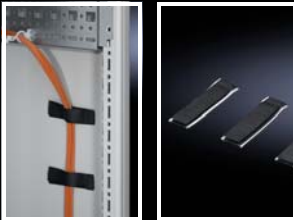

## Nylon loop tape holders

- For simple, fast cable attachment
- Toolless mounting in the system punchings with 10.5 x 12.5 mm, with a quarter rotation
- Direct use on the horizontal TS frame section, on the support strips and mounting angles of the TS-IT 482.6 mm (19") interior installation, on the cable route or on punched sections with mounting flanges
- Length of nylon loop tape: 400 mm

### Material:

- Plastic

### Supply includes:

- 10 holders including nylon loop tape

Packs of	Model No.
10 pc(s).	<b>5502.155</b>

## Nylon loop cable holder

### Self-adhesive

Suitable for universal use in all network enclosures and server racks, wall-mounted enclosures, mounting plates, gland plates.

### Material:

- Woven polyamide 6.6

### Colour:

- Black

Size Length x width mm	Packs of	Model No.
70 x 16	10 pc(s).	<b>7111.350</b>

## Snap-in cable routing

### for clipping into the system punchings.

Cable routing suitable for universal use, for toolless, fast assembly, in two variants:

For locking

- User-friendly opening for cable management via locating points
- For cable diameters 14 – 19 mm
- For system punchings 6.2 mm

For routing

- User-friendly opening for cable management
- For cable diameters 10.2 – 12.7 mm
- For system punchings 4.7 mm

### Material:

- Polyamide 6.6, self-extinguishing to UL 94-V2

### Colour:

- Natural

Version	Packs of	Model No.
For locking For system punchings 6.2 mm	10 pc(s).	<b>7111.300</b>
For twisting For system punchings 4.7 mm	10 pc(s).	<b>7111.310</b>