


482.6 mm (19") installation system

482.6 mm (19") installation

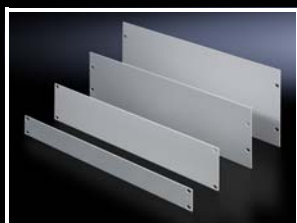

Blanking plates, 482.6 mm (19")

For installation in electronic enclosures or housings.


Material:

– Aluminium

Surface finish:

– Natural anodised

U	Packs of	Model No.
1	3 pc(s).	1931.200
2	3 pc(s).	1932.200
3	3 pc(s).	1933.200
4	3 pc(s).	1934.200
6	3 pc(s).	1936.200
7	3 pc(s).	1935.200
9	3 pc(s).	1939.200
12	3 pc(s).	1937.200

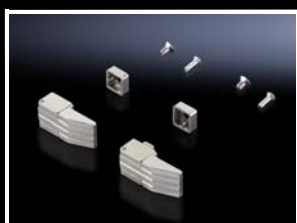

Hinge

for blanking plates

Material:

– Die-cast zinc


Surface finish:

– Zinc-plated

Supply includes:

– Assembly parts

Packs of	Model No.
2 pc(s).	1950.000

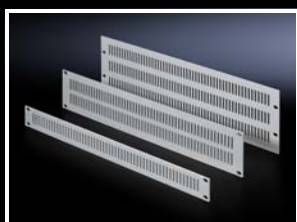

Ventilated front panels

For venting enclosures and housings.

Material:

– Aluminium

Surface finish:

– Natural anodised

Width	U	Packs of	Model No.
482.6 mm (19")	1	3 pc(s).	2231.000
482.6 mm (19")	2	3 pc(s).	2232.000
482.6 mm (19")	3	3 pc(s).	2233.000



Air baffle plate

for TS-IT

- To separate the hot/cold zones within an enclosure with aisle containment or when using an LCP system
- With all-round brush strip for collision-free shielding with installed bar systems on the outer mounting level
- For width 800 mm, 6 x 1 U blanking panel additionally included

Material:

– Sheet steel, plastic UL 94 V0

Surface finish:

– Spray-finished

Colour:

– RAL 9005

Supply includes:

– Assembly parts

Width x height mm	Packs of	Model No.
600 x 2000	1 set(s)	5501.805
800 x 2000	1 set(s)	5501.815
600 x 2200	1 set(s)	5501.825
800 x 2200	1 set(s)	5501.835

