


482.6 mm (19") installation system

Patch panels

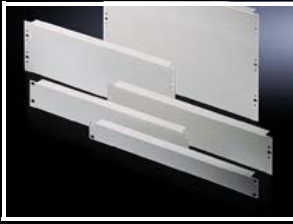

Blanking panel, 482.6 mm (19")

As an extension cover or for population as required.

Material:

- Sheet steel

Colour: RAL 7035

U	Installation height mm	Packs of	Model No.
1	44	2 pc(s).	7151.035
1.5	66	2 pc(s).	7157.035
2	88	2 pc(s).	7152.035
3	132.5	2 pc(s).	7153.035
6	266	2 pc(s).	7156.035



Colour: RAL 9005

U	Installation height mm	Packs of	Model No.
1	44	2 pc(s).	7151.005
2	88	2 pc(s).	7152.005
3	132.5	2 pc(s).	7153.005
6	266	2 pc(s).	7156.005



Blanking panel, 1 U

Toolless attachment, 482.6 mm (19")

The blanking panel is used to seal unused areas within the 482.6 mm (19") mounting level. Quick toolless attachment means that it is easily integrated anywhere, and can also be removed again if necessary. The consistent use of blanking panels ensures targeted air routing in partially populated racks.

Material:

- Plastic, ABS

Fire protection:

- Self-extinguishing to UL 94-V0, non-halogen-free

Colour	Packs of	Model No.
RAL 7035	10 pc(s).	7151.110
RAL 9005	10 pc(s).	7151.105

