

482.6 mm (19") installation system

482.6 mm (19") installation



Adaptor, metric to 21"/19"

With this adaptor, 482.6 mm (19") assemblies may be fastened to metric (535 mm) mounting angles, or combined systems may be configured.

Material:

- Extruded aluminium section

Supply includes:

- Assembly parts

SU	U	Packs of	Model No.
2	1	2 pc(s).	7246.010
6	3	2 pc(s).	7246.030
11	6	2 pc(s).	7246.060



Drawer, 2 U, 3 U

for one 482.6 mm (19") mounting level

For front attachment to mounting angles, 482.6 mm (19"). With cover and telescopic slides to accommodate assignment lists, operating manuals and small parts. The small version of the 2 U variant is also suitable for mounting inside a swing frame.


Material:

- Sheet steel

Supply includes:

- Drawer fully assembled including security lock 12321

Height	Clearance openings		Installation depth mm	Colour		Packs of	Model No.
	Width mm	Depth mm		RAL 7035	RAL 9005		
2 U	411	244	250	■	-	1 pc(s).	7282.135
2 U	411	419	427	■	-	1 pc(s).	7282.035
2 U	411	419	427	-	■	1 pc(s).	5502.305
3 U	411	419	427	■	-	1 pc(s).	7283.035
3 U	411	419	427	-	■	1 pc(s).	5502.325

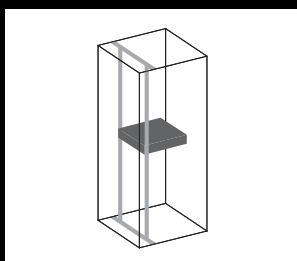

Small equipment box, 4 U, shielded

for one 482.6 mm (19") mounting level

For accommodation of small equipment and other accessories within a partitioned 482.6 mm (19") installation level. The small equipment box contains an adjustable mounting base which can be used to further sub-divide the box.

Material:

- Sheet steel

Surface finish:

- Spray-finished

Colour:

- RAL 9005

Load capacity:

- 200 N surface load, static

Supply includes:

- Small equipment box with brush strip
- 1 shelf



Contact width mm	Contact depth mm	Width mm	Height mm	Depth mm	Packs of	Model No.
405	300	427	170	400	1 pc(s).	5501.900