

Compact enclosures AX

Operating housings AX for desktop TFT up to 24"



System accessories Page 62

For the installation of commercially available desktop TFTs with a screen diagonal of up to 24" in the formats 16:9/16:10.

Material:

- Enclosure: Sheet steel
- Door: Sheet steel, all-round foamed-in PU seal
- Handle strips: Aluminium
- Cover caps: Plastic
- Viewing window: Single-pane safety glass
- TFT holder: Sheet steel

Surface finish:

- Enclosure and door: Powder-coated on the outside, textured paint
- Handle strip: Natural anodised

Colour:

- Enclosure and door: RAL 7035
- Cover caps: similar to RAL 7024

Protection category IP to IEC 60 529:

- IP 65

Supply includes:


- Enclosure with door, cut-out and reinforcement for support arm connection Ø 130 mm
- Viewing window, single-pane safety glass
- Holder for desktop TFT with VESA 75/100 locator
- Side handle strips and cover caps
- Rear door with r/h hinge
- Cam lock with 3 mm double-bit insert

Note:

- The support arm connection and door hinge may be swapped over by rotating the enclosure
- Optional: Support arm connection Ø 130 mm, pre-formed off-centre in the reinforcement plate, easily drilled out
- Lock insert may be exchanged for mini-comfort handle AX, 27 mm lock inserts, type A

Approvals:

- UL
- cUL
- CSA

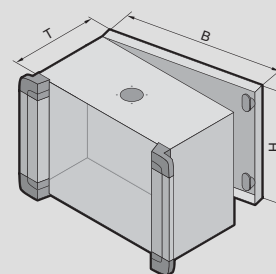

Operating housing AX for desktop TFT up to 24"

Width (B) mm	Packs of	650	Page
Height (H) mm		450	
Depth (T) mm		155	
Model No.	1 pc(s).	6321.050	
Weight, approx. kg		18.0	
Cam lock		2	
Accessories			
Mini-comfort handle AX for lock inserts or semi-cylinders	1 pc(s).	2537.100	67
Mini-comfort handle AX with security lock insert, lock E1	1 pc(s).	2537.200	67
Mini-comfort handle AX for padlock and lock inserts or semi-cylinders	1 pc(s).	2537.300	67
Lock inserts		see page	68