

Universal consoles TP



System accessories Page 507 Monitors, keyboards Page 706/707 Climate control Page 307

Material:

- Enclosure, gland plates: Sheet steel 1.5 mm
- Door: Sheet steel, 2.0 mm
- Mounting plate: Sheet steel 3.0 mm

Surface finish:

- Enclosure and door: Dipcoat primed, powder-coated on the outside, textured paint
- Mounting plate and gland plates: Zinc-plated

Colour:

- RAL 7035

Protection category IP to IEC 60 529:

- IP 55

Protection category NEMA:

- NEMA 12

Supply includes:

- Enclosure with door(s)
- Mounting plate
- Gland plates

Note:

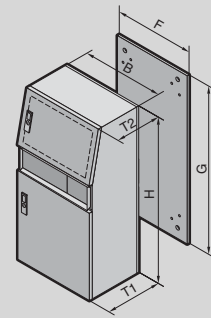
- For universal console with short front door: The drawer or desk section should be fitted in order to preserve the protection category. The keyboard drawer may be installed without a mounting plate.



 

Approvals:

- UL
- CSA
- TÜV
- Germanischer Lloyd
- Russian Maritime Register of Shipping
- Lloyds Register of Shipping
- VDE

Technical details:

Available on the Internet



						
Design	Packs of	with short front door			with tall front door	Page
Width (B) mm		600			600	
Height (H) mm		1300			1300	
Depth, bottom (T1) mm		500			500	
Depth, top (T2) mm		417.5			417.5	
Mounting plate width (F) mm		499			499	
Mounting plate height (G) mm		1196			1196	
Model No.	1 pc(s).	2694.500			2695.500	
Weight kg		77.0			80.0	
Also required						
Drawer	1 pc(s).	-	-	4757.500	-	117
Desk section	1 pc(s).	2696.500	2696.500	-	-	117
Accessories						
Base/plinth, complete		see page			see page	519
Cross member	2 pc(s).	8601.450			8601.450	520
Support strips	20 pc(s).	2325.000			2325.000	575
Cable clamp rails	2 pc(s).	4191.000			4191.000	665
Lock systems		from page			from page	562