

Optipanel



System accessories Page 507 Support arm systems Page 135 Stand systems Page 164 Industrial Workstations Page 120

Material:

- Enclosure: Extruded aluminium section
- Corner pieces: Die-cast zinc
- Corner protectors: Plastic

Colour:

- Enclosure: Natural anodised
- Corner pieces: RAL 7035
- Corner protectors: Similar to RAL 7024

Protection category IP to IEC 60 529:

- IP 65

Supply includes:

- Seals

Note:


- The support arm connection may be swapped over by rotating the enclosure

Approvals:

- UL

Technical details:

Available on the Internet

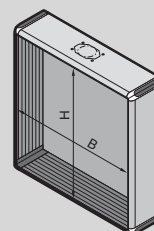

	Packs of	430	482.6	482.6	520	520	520	Page
For front panel width (B) mm								
For front panel height (H) mm		343	310.3	354.8	400	500	600	
Installation depth mm		100	100	100	100	150	150	
Model No.	1 pc(s).	6380.020¹⁾	6380.000	6380.040¹⁾	6380.400	6380.410	6380.510	6380.610
Weight kg		5.3	6.2	6.6	5.8	7.3	8.3	9.2

Version

Support arm connection □ 120 x 65 mm		■	■	■	■	–	–	–
Support arm connection Ø 130 mm		–	–	–	–	■	■	■
Hinged rear panel ²⁾		■	■	■	■	■	■	■
Seals and assembly parts for front panels		–	–	–	■	■	■	■

Accessories

Front panel	1 pc(s).	–	6028.010	–	6028.014	6028.014	6028.015	6028.016	704
Handle set, horizontal	1 pc(s).	–	6385.010	6385.010	–	–	–	–	700
Mounting bracket for interior installation	4 pc(s).	6205.100	6205.100	6205.100	6205.100	6205.100	6205.100	6205.100	617
Mounting bracket	4 pc(s).	4597.000	4597.000	4597.000	4597.000	4597.000	4597.000	4597.000	617
Earthing plate	1 pc(s).	2570.500	2570.500	2570.500	2570.500	2570.500	2570.500	2570.500	645
Spring nut M5	50 pc(s).	6108.000	6108.000	6108.000	6108.000	6108.000	6108.000	6108.000	625

¹⁾ To fit TFT monitors, see page 706.

²⁾ With 3 mm double-bit lock insert, may be exchanged for 41 mm lock inserts, type C, see page 570, plastic handles and T handles, type C, see page 569.