

Operating housing with handle strips



System accessories P. 507 Support arm systems P. 135 Stand systems P. 164 Command panel housing with door, stainless steel P. 189

Material:

- Enclosure and door: Sheet steel
- Handle strips: Aluminium
- Front panel: Aluminium
- Cover caps: Plastic

Surface finish:

- Enclosure and door: Dipcoat-primed, powder-coated on the outside, textured paint
- Handle strip: Natural anodised
- Front panel: Natural anodised

Colour:

- Enclosure and door: RAL 7035
- Handle strip: Natural anodised
- Front panel: Natural anodised
- Cover caps: similar to RAL 7024

Protection category IP to IEC 60 529:



- IP 55

Supply includes:

- Enclosure with cut-out and reinforcement for support arm connection \varnothing 130 mm
- Front with maximum cut-out, covered with easily machinable 3 mm aluminium front panel
- Side handle strips and cover caps
- Cam lock with 3 mm double-bit insert
- Integral interior installation bracket with TS system punchings

Note:

- The support arm connection and door hinge may be swapped over by rotating the enclosure
- Optional: Support arm connection \varnothing 130 mm, preformed off-centre in the reinforcement plate, easily drilled out

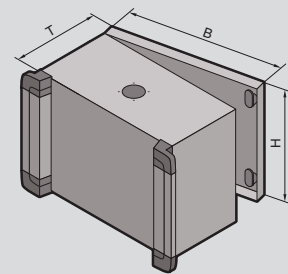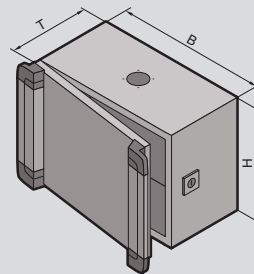

- Lock systems for servicing access from the front: 41 mm lock inserts, lock cylinder, plastic handles and T-handles, type C
- Lock systems for servicing access from the rear: 41 mm lock inserts, type A, lock cylinder, plastic handles and T-handles, type B

Approvals:

- CSA

Technical details:

Available on the Internet

Width (B) mm	Packs of	300	300	380	380	380	Page
Height (H) mm		200	300	300	380	380	
Depth (T) mm		155	210	210	210	210	
Model No.	1 pc(s).	6320.000	6315.100	6315.200	6315.300	6320.300	
Weight kg		4.5	7.0	7.5	9.8	9.8	
Servicing access	from the front	–	■	■	■	–	
	from the rear	■	–	–	–	■	
Accessories							
TS punched section with mounting flange, 17 x 73 mm	4 pc(s).	–	8612.130	8612.130	–	–	606
TS punched rail 18 x 38 mm		–	–	–	–	–	609
TS support strips	20 pc(s).	–	–	–	4594.000	4594.000	609
Mounting bracket	4 pc(s).	4597.000	4597.000	4597.000	4597.000	4597.000	617
	4 pc(s).	6205.100	6205.100	6205.100	6205.100	6205.100	617
Mini-comfort handle		–	–	–	–	see page	567

Operating housing with handle strips

Width (B) mm	Packs of	500	500	600	600	600	Page
Height (H) mm		500	500	380	600	600	
Depth (T) mm		210	210	210	210	210	
Model No.	1 pc(s).	6315.400	6320.400	6320.500	6315.600	6320.600	
Weight kg		16.8	16.8	15.4	22.8	22.8	
Servicing access	from the front	■	-	-	■	-	
	from the rear	-	■	■	-	■	
Accessories							
TS punched section with mounting flange, 17 x 73 mm	4 pc(s).	8612.150	8612.150	-	8612.160	8612.160	606
TS punched rail 18 x 38 mm	4 pc(s).	8612.250	8612.250	-	8612.260	8612.260	609
TS support strips	20 pc(s).	4695.000	4695.000	4594.000	4696.000	4696.000	609
Mounting bracket	4 pc(s).	4597.000	4597.000	4597.000	4597.000	4597.000	617
	4 pc(s).	6205.100	6205.100	6205.100	6205.100	6205.100	617
Mini-comfort handle		-	see page	see page	-	see page	567



Support arm system CP 60/120/180

see page 135

New