

## Door variants

### Tubular door frame

#### for TS, TS-IT, SE

To fit sheet steel doors prepared for a tubular door frame.

#### Material:

- Tube section: Sheet steel
- Corner connectors: Plastic


#### Surface finish:

- Tube section: Zinc-plated

#### Supply includes:

- Assembly parts

For doors		Packs of	Model No.
Width mm	Height mm		
300	2000	1 set(s)	<b>5501.200</b>
400	2000	1 set(s)	<b>5501.210</b>

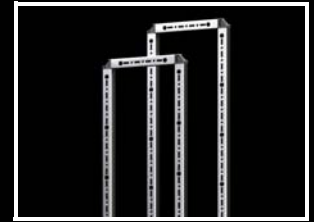

### Glazed door

#### for TS, TS-IT

Instead of a sheet steel door or rear panel.

#### Material:

- Frame: Extruded aluminium section
- Corner pieces: Die-cast zinc
- Viewing window: Single-pane safety glass, 3 mm

#### Surface finish:

- Powder-coated

#### Colour:

- Frame and corner pieces: RAL 7035
- Viewing window (printed mask on the inside): RAL 9005

#### Protection category IP to IEC 60 529:

- IP 55

#### Supply includes:

- Glazed door frame with safety glass
- Locking rod with double-bit lock insert
- 180° hinges (4)
- Visible area: W -140 mm, H -160 mm

For enclosures		Model No.
Width mm	Height mm	
600	1800	<b>8610.685</b>
800	1800	<b>8610.885</b>
600	2000	<b>8610.605</b>
800	2000	<b>8610.805</b>
600	2200	<b>8610.625</b>
800	2200	<b>8610.825</b>



#### Also required:

- When mounting instead of the rear panel: Lock components for frame 8800.040, see page 550



### Handle adaptor

The handle adaptor compensates for the design chamfer in the door profile to enable installation of the comfort handle.

#### Material:

- Plastic

#### Supply includes:

- 1 adaptor plate
- 1 bolt to extend the screw-on dome
- 2 assembly screws

#### For glazed door TS

Colour	Model No.
RAL 7035	<b>8611.080</b>

#### For designer door IW and PC, bottom door

Colour	Model No.
RAL 7035	<b>8611.300</b>

