

### TS punched section with mounting flange, 17 x 73 mm

#### Depth-variable

To fit the outer and inner mounting level.


| Length mm | Packs of | Model No. |
|-----------|----------|-----------|
| 530 – 700 | 2 pc(s). | 7000.678  |

#### Material:

– Sheet steel

#### Surface finish:

– Zinc-plated

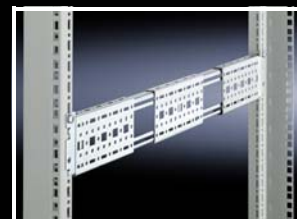

### TS punched section with mounting flange, 23 x 73 mm

The alternative to the TS punched section with mounting flange 17 x 73 mm, see page 606, with punchings for captive nuts/threaded blocks instead of the slotted holes top and bottom. Simply locate and secure.

#### Installation options:

■ On the vertical TS, SE enclosure section

#### Material:

– Sheet steel

#### Surface finish:

– Zinc-plated

#### Supply includes:

– Assembly screws

#### For the inner mounting level

| For enclosure width/depth mm | Packs of | Model No. |
|------------------------------|----------|-----------|
| 500                          | 4 pc(s). | 8612.550  |
| 600                          | 4 pc(s). | 8612.560  |
| 800                          | 4 pc(s). | 8612.580  |
| 1000                         | 4 pc(s). | 8612.500  |
| 1200                         | 4 pc(s). | 8612.520  |



#### Accessories:

– Screws, see page 625  
– Threaded blocks, captive nuts, see page 624

#### Configuration examples:

See page 598

