

Interior installation

Rail systems



Support rail 65 x 42 mm for TS, SE

Benefits:

- For heavy assemblies up to 5000 N per support rail

Permissible static load:

- 10000 N per enclosure

Material:

- Steel


Surface finish:

- Zinc-plated

Supply includes:

- Assembly parts

For enclosure width mm	Packs of	Model No.
600	2 pc(s).	8612.960
800	2 pc(s).	8612.980

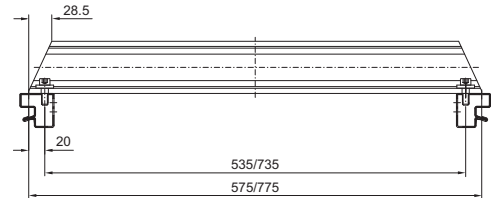

Support rails TS 35/15

to EN 60 715 for TS, SE

- Mounting on the TS vertical section via
- Snap-on nut M8, 8800.808, see page 618
 - Assembly block see page 610 or
 - Adaptor rail, see page 610

For enclosure width/depth mm	Support rails length mm	Packs of	Model No.
500	455	6 pc(s).	4933.000
600	555	6 pc(s).	4934.000
800	755	6 pc(s).	4935.000
1200	1155	6 pc(s).	4937.000

Support rails TS 35/7.5 and TS 35/15

to EN 60 715 for KL, KL-HD, AE

Length sized to the enclosure width

For enclosure width mm	Support rails length mm	Version	Packs of	Model No.
150	137	TS 35/7.5	10 pc(s).	2314.000
200	187		10 pc(s).	2315.000
300	287		10 pc(s).	2316.000
400	387	TS 35/15	10 pc(s).	2317.000
500	487		10 pc(s).	2318.000
600	587		10 pc(s).	2319.000

Support rails

to EN 60 715

Standard length 2 m

Version	Length	Packs of	Model No.
TS 35/15	2 m	6 pc(s).	2313.150
TS 35/7.5	2 m	6 pc(s).	2313.750

Mounting clip

for support rails

For fast, secure attachment of

- Cable ducts
- Mounting plates
- Mounting angles

on support rail TS 35/7.5 and TS 35/15 to EN 60 715.

Simply pre-assemble the mounting clip on the part to be installed, then snap into position on the support rail.

Packs of	Model No.
30 pc(s).	2309.000