


Cable management

Gland plates

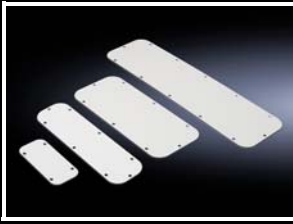

Metal gland plates

As spare/replacement part for the standard gland plates supplied loose.

Material:

– Sheet steel

Colour:

– RAL 7035

Protection category IP to IEC 60 529:

– IP 66 when mounting in the usual position at the bottom

Note:


– The applicable size may be taken from the respective product ordering page

Size	Design	Packs of	Model No.
1	Solid	1 pc(s).	2560.400
2	Solid	6 pc(s).	1158.500
3	Solid	1 pc(s).	2561.400
4	Solid	1 pc(s).	2562.400
5	Solid	1 pc(s).	2563.150


+ **Accessories:**

– Cable glands made from polyamide or brass, see page 658


2560.400

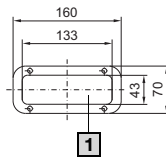


2561.400

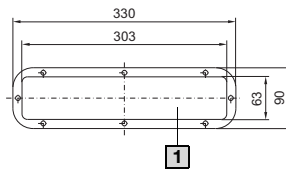


2562.400

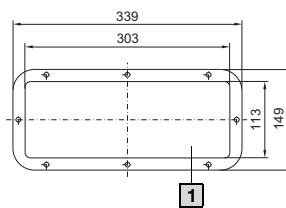

2563.150

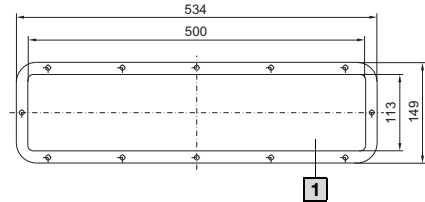

1158.500

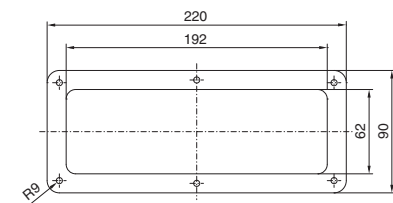

1 Area available for population



Gland plate

for metric cable glands, for EL

Folded gland plate with foamed-in seal and pre-punched, knock-out holes for metric cable glands M12, M20, M25, M32, M40.

Material:

– Sheet steel, 1.5 mm

Colour:

– RAL 7035

Protection category IP to IEC 60 529:

– IP 55

Packs of	Model No.
1 pc(s).	7705.235

