

Keyboards, supports and drawers



Built-in keyboard 482.6 mm (19¹)/4 U

with integral touchpad

The integral touchpad eliminates the need to install an additional, correct protection category mouse is no longer required, and cabling is also reduced. The short stroke keys are easily identified by edge embossing, less force is required to operate them and they have good positive key actuation.

Benefits:

- The separate number pad enables the parameters to be entered quickly
- Sealed, wipeable surface finish
- High level of mechanical and chemical resistance as per DIN 42 115

Technical specifications:

- Number of keys: 105
- Front panel dimensions: 482.6 x 177.0 mm (19¹ x 4 U)
- Installation depth: 23 mm
- 12 M5 x 20 threaded bolts at the rear
- Actuation travel/force: 0.3 mm/2.6 N
- Service life: 3 million switching cycles
- Operating temperature: -40°C...+90°C
- Touchpad resolution, capacitive: 40 pixels/mm
- Interfaces: USB

Material:

- Front panel: Aluminium

Protection category IP to IEC 60 529:

- IP 65 (at the front)


Supply includes:

- Y connection cable, length 1.8 m
- USB connector
- Seal
- Drilling template
- Assembly parts for surfaces

Keyboard layout	Packs of	Model No.
German	1 pc(s).	6446.030

! Also required:

- Mounting kit 6053.800 (when installing in Comfort Panel), see page 705
- Mounting kit 6053.500 (when installing in Optipanel), see page 705

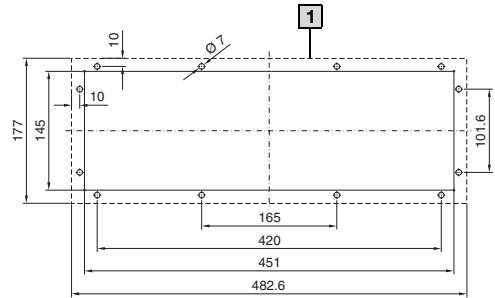

1 Support surface



Fold-out tray

for keyboard and mouse

- For installation in 600 and 800 mm wide doors
- 482.6 mm (19¹) swing frames and enclosures

Standard double-bit lock insert which may be exchanged for lock inserts 27 mm, type A, see page 570 and for lock cylinder 2571.000, see page 571

Material:

- Flap: Sheet steel
- Side parts: Cast aluminium
- Tray: Extruded aluminium section

Surface finish:

- Cover, side parts: Textured paint
- Tray: Natural anodised

Colour:

- Cover, side parts: RAL 7035


Protection category IP to IEC 60 529:

- IP 55

+ Accessories:

- Mousepad support, pull-out, see page 709

Mounting cut-out

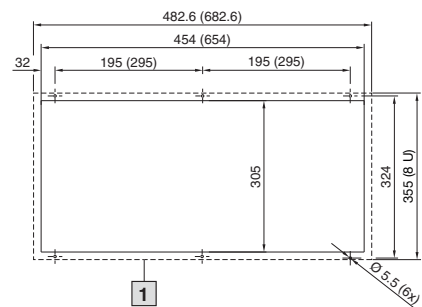

1 Support surface

For door width mm	External dimensions W x H x D mm	Installation depth mm	Max. keyboard size W x H x D mm	Model No.
600	482.6 (19 ¹) x 355 (8 U) x 126	93	405 x 50 x 250 405 x 50 x 195 ¹⁾	2379.600
800	682.6 x 355 (8 U) x 126	93	605 x 50 x 250 605 x 50 x 195 ¹⁾ 475 ¹⁾ x 50 x 250	2379.800

¹⁾Maximum keyboard size with holder for mouse