

Mounting frame, 482.6 mm (19")

for TS, TS IT

Firmly linked 482.6mm (19") mounting frame for integration of a 482.6 mm (19") mounting level within a TS frame structure. Profiles analogous to TS IT for complete system compatibility, incl. tool-free assembly. Depth-variable mounting between the roof and base frames. Individual height units bi-directionally numbered. Mounting frame at the front, prepared for the integration of cable management and Dynamic Rack Control (RFID), mounting frame at the rear for space-saving integration of the PDU busbar, in the Zero-U space on both sides.

Material:

- Sheet steel

Surface finish:

- Primed

Colour:

- RAL 9005

Load capacity:

- Up to 10,000 N static load, with even load distribution on two 482.6 mm (19") mounting frames, with full installation.


 
Supply includes:

- Assembly parts

Note:

- The outer mounting level of the enclosure frame is left free for other installed equipment; all-round compartmentalisation with air baffle plates is supported

For enclosure width mm	For enclosure height mm	Installation position	Packs of	Model No.
600	1800	Front	1 pc(s).	5501.242
600	1800	Rear	1 pc(s).	5501.245
800	1800	Front	1 pc(s).	5501.252
800	1800	Rear	1 pc(s).	5501.255
600	2000	Front	1 pc(s).	5501.262
600	2000	Rear	1 pc(s).	5501.265
800	2000	Front	1 pc(s).	5501.272
800	2000	Rear	1 pc(s).	5501.275
600	2200	Front	1 pc(s).	5501.282
600	2200	Rear	1 pc(s).	5501.285
800	2200	Front	1 pc(s).	5501.292
800	2200	Rear	1 pc(s).	5501.295

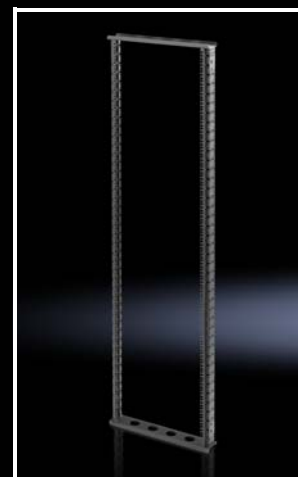

Air baffle plates for TS IT 482.6 mm (19") mounting frames

With all-round brush strip for collision-free shielding with installed bar systems on the outer mounting level.

Applications:

- To separate the hot/cold zones within an enclosure with aisle containment or when using an LCP system.

Material:

- Sheet steel
- Blanking panel: Plastic, to UL 94-V0
- Brush strip: Plastic, UL 94-V0

Surface finish:

- Spray-finished

Colour:

- RAL 9005

Supply includes:

- Air baffle plate with all-round brush strip

For enclosure width mm	For enclosure height mm	Product-specific scope of supply	Packs of	Model No.
600	1200	–	1 pc(s).	5501.855
800	1200	1 blanking panel, 3 U	1 pc(s).	5501.865
600	1800	–	1 pc(s).	5501.875
800	1800	2 blanking panels, 3 U	1 pc(s).	5501.885
600	2000	–	1 pc(s).	5501.905
800	2000	2 blanking panels, 3 U	1 pc(s).	5501.915
600	2200	–	1 pc(s).	5501.925
800	2200	2 blanking panels, 3 U	1 pc(s).	5501.935

