
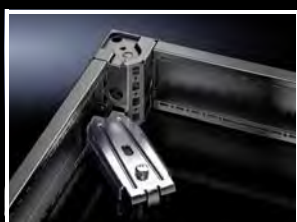


# Base/plinth

## Base/plinth system VX

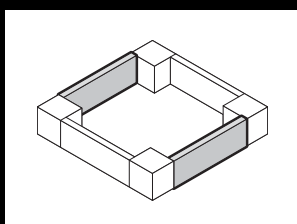

### Base/plinth trim panels, sides

#### Stainless steel

To finish off a base/plinth unit at the side and for additional stabilisation or for interior configuration of bayed base/plinths. One 200 mm high or two 100 mm high trim panels may optionally be fitted on 200 mm high base/plinths.

#### Material:

- Base/plinth trim panels: Stainless steel 1.4301 (AISI 304)

#### Surface finish:

- Brushed, grain size 400

#### Supply includes:

- 2 base/plinth trim panels
- Assembly parts

For enclosure depth mm	Height mm	Model No.
400	100	<b>8620.070</b>
500	100	<b>8620.071</b>
600	100	<b>8620.072</b>
400	200	<b>8620.080</b>
500	200	<b>8620.081</b>
600	200	<b>8620.082</b>



#### Accessories:

- Base/plinth installation bracket, see page 89

### Transport castors

For locating onto the base/plinth corner piece, 100 or 200 mm high.

#### Load capacity:

- Maximum permissible load per twin castor: 1000 N

#### Supply includes:

- 4 twin castors, 2 x with, 2 x without locks

#### Colour:

- RAL 9005

Floor clearance mm	Model No.
100	<b>8100.700</b>



#### Accessories:

- Base/plinth trim panels, sides, for stabilisation, see page 86

### Base mounting plate

For attaching the base/plinth to the floor. For assembly screws up to 12 mm Ø.

#### Material:

- Sheet steel

#### Surface finish:

- Zinc-plated

P. of	Model No.
10 pc(s).	<b>2817.000</b>