
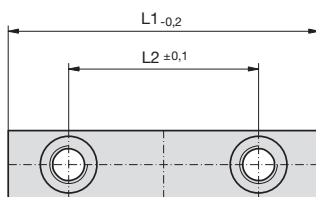





### Führungsleisten

### Guide strips

### Barres de guidage

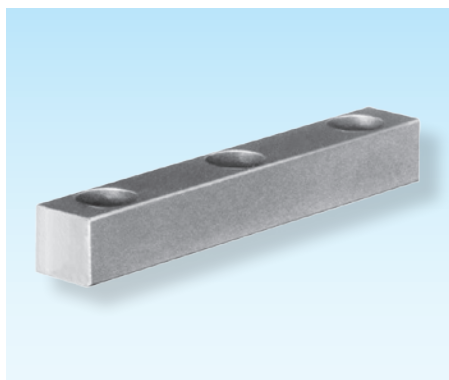

 **Type A**

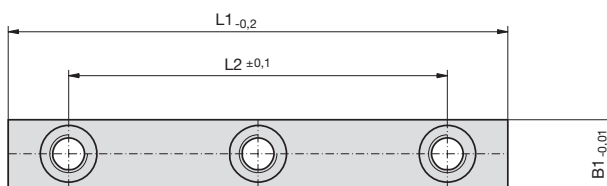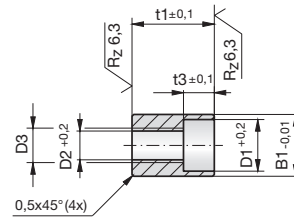

**Type B**

**Z4248-**

Mat.: ST  
58 +2HRC



Z4248-B1-t1-L1



5

B1	t1	L1	Type	t3	L2	D1	D2	D3
12	11	50	A	5,7	30	10	5,3	M6
12	11	60	A	5,7	40	10	5,3	M6
12	11	70	B	5,7	50	10	5,3	M6
12	11	75	B	5,7	60	10	5,3	M6
12	11	80	B	5,7	60	10	5,3	M6
12	11	90	B	5,7	70	10	5,3	M6
12	16	100	B	5,7	80	10	5,3	M6
12	16	120	B	5,7	100	10	5,3	M6
12	16	140	B	5,7	120	10	5,3	M6
12	16	160	B	5,7	140	10	5,3	M6
12	16	180	B	5,7	160	10	5,3	M6
18	16	100	A	6,8	76	11	6,8	M8
18	16	120	A	6,8	96	11	6,8	M8
18	16	140	B	6,8	116	11	6,8	M8
18	16	160	B	6,8	136	11	6,8	M8
18	16	180	B	6,8	156	11	6,8	M8
24	21	140	B	6,8	116	11	6,8	M8
24	21	160	B	6,8	136	11	6,8	M8
24	21	180	B	6,8	156	11	6,8	M8
24	21	200	B	6,8	176	11	6,8	M8
24	21	220	B	6,8	196	11	6,8	M8

Z4248-

