
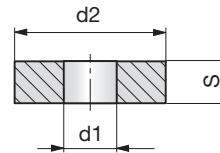


Nachschleifscheiben

Regrinding washers

Rondelles de réglage

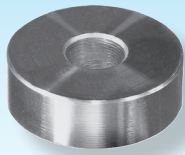

SN2514-

Mat.: 1.0501
52 ±2HRC

 SN2514-d2



d2

d1

s

20

6,5

8

25

8,5

8

32

10,5

8

40

12,5

10

50


16,5

10

Gewindeflansche

Screwed flanges

Flasques taraudée

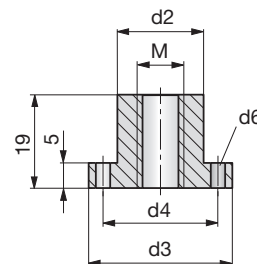

SN2515-

Mat.: 1.0501
52 ±2HRC

 SN2515-d3



d3

d2

M

d4

d6

20

10

M6

14

3,2

25

12,5

M8

18

4,2

32

16

M10

25

4,2

40

20

M12

30

4,2

50

25

M16

40

4,2