


Angießbuchsen

Sprue bushes

Buse d'injection

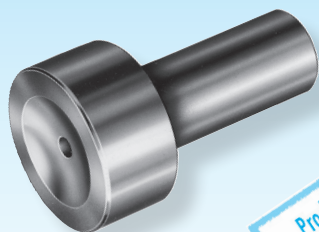


Produktänderung
Product modification
Modification des produits

Z37-

Mat.: 1.2826
~55 HRC/~DIN 16752



Z37-Type

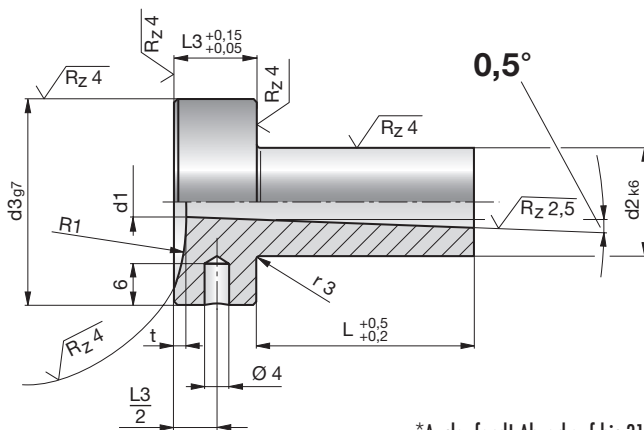

*Auslaufend! Abverkauf bis 31.12.2023.
Discontinued! Sales until 31.12.2023.
Discontinu  ! Ventes jusqu'au 31.12.2023.


Type	d1	d2	L	L3	R1	t	d3	Type	d1	d2	L	L3	R1	t	d3	Type	d1	d2	L	L3	R1	t	d3
1020	3	16	57	18	15,5	3	38	1430	3	20	57	18	40	3	38	1680	6	20	77	18	15,5	3	38
1025	3	16	77	18	15,5	3	38	1435	3	20	77	18	40	3	38	1685	6	20	97	18	15,5	3	38
1050	3	16	57	18	40	3	38	1440	3	20	97	18	40	3	38	1690	6	20	117	18	15,5	3	38
1055	3	16	77	18	40	3	38	1460	3	20	57	18	0	0	38	1710	6	20	77	18	40	3	38
1080	3	16	57	18	0	0	38	1465	3	20	77	18	0	0	38	1715	6	20	97	18	40	3	38
1085	3	16	77	18	0	0	38	1470	3	20	97	18	0	0	38	1720	6	20	117	18	40	3	38
1110	4	16	57	18	15,5	3	38	1490	4	20	57	18	15,5	3	38	1740	6	20	77	18	0	0	38
1115	4	16	77	18	15,5	3	38	1495	4	20	77	18	15,5	3	38	1745	6	20	97	18	0	0	38
1120	4	16	97	18	15,5	3	38	1500	4	20	97	18	15,5	3	38	1750	6	20	117	18	0	0	38
1150	4	16	57	18	40	3	38	1505	4	20	117	18	15,5	3	38								
1155	4	16	77	18	40	3	38	1520	4	20	57	18	40	3	38								
1160	4	16	97	18	40	3	38	1525	4	20	77	18	40	3	38								
1185	4	16	57	18	0	0	38	1530	4	20	97	18	40	3	38								
1190	4	16	77	18	0	0	38	1535	4	20	117	18	40	3	38								
1195	4	16	97	18	0	0	38	1550	4	20	57	18	0	0	38								
1210	5	16	57	18	15,5	3	38	1555	4	20	77	18	0	0	38								
1215	5	16	77	18	15,5	3	38	1560	4	20	97	18	0	0	38								
1240	5	16	57	18	40	3	38	1565	4	20	117	18	0	0	38								
1245	5	16	77	18	40	3	38	1590	5	20	77	18	15,5	3	38								
1270	5	16	57	18	0	0	38	1595	5	20	97	18	15,5	3	38								
1275	5	16	77	18	0	0	38	1600	5	20	117	18	15,5	3	38								
1310	6	16	77	18	15,5	3	38	1620	5	20	77	18	40	3	38								
1340	6	16	77	18	40	3	38	1625	5	20	97	18	40	3	38								
1370	6	16	77	18	0	0	38	1630	5	20	117	18	40	3	38								
1400	3	20	57	18	15,5	3	38	1650	5	20	77	18	0	0	38								
1405	3	20	77	18	15,5	3	38	1655	5	20	97	18	0	0	38								
1410	3	20	97	18	15,5	3	38	1660	5	20	117	18	0	0	38								

Angießbuchsen

Sprue bushes

Buse d'injection

2

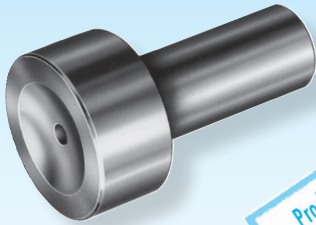


Produktänderung
Product modification
Modification des produits

Z37-

Mat.: 1.2826
~55 HRC/~DIN 16752

Z37-Type

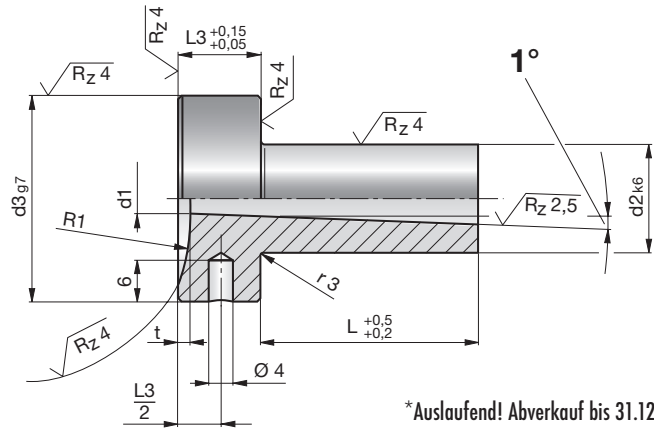

*Auslaufend! Abverkauf bis 31.12.2023.
Discontinued! Sales until 31.12.2023.
Discontinu ! Ventes jusqu'au 31.12.2023.

Type	d1	d2	L	L3	R1	t	d3	Type	d1	d2	L	L3	R1	t	d3	Type	d1	d2	L	L3	R1	t	d3
410	2,5	12	22	13	15,5	1,5	28	570	3,5	16	47	18	15,5	3	38	685	4,5	20	97	18	40	3	38
415	2,5	12	27	13	15,5	1,5	28	575	3,5	16	57	18	15,5	3	38	690	4,5	20	117	18	40	3	38
420	2,5	12	37	13	15,5	1,5	28	577	3,5	16	67	18	15,5	3	38	695	4,5	20	27	18	0	0	38
425	2,5	12	47	13	15,5	1,5	28	580	3,5	16	77	18	15,5	3	38	700	4,5	20	37	18	0	0	38
430	2,5	12	57	13	15,5	1,5	28	585	3,5	16	27	18	40	3	38	705	4,5	20	47	18	0	0	38
435	2,5	12	22	13	40	1,5	28	590	3,5	16	37	18	40	3	38	710	4,5	20	57	18	0	0	38
440	2,5	12	27	13	40	1,5	28	595	3,5	16	47	18	40	3	38	712	4,5	20	67	18	0	0	38
445	2,5	12	37	13	40	1,5	28	600	3,5	16	57	18	40	3	38	715	4,5	20	77	18	0	0	38
450	2,5	12	47	13	40	1,5	28	602	3,5	16	67	18	40	3	38	717	4,5	20	87	18	0	0	38
455	2,5	12	57	13	40	1,5	28	605	3,5	16	77	18	40	3	38	720	4,5	20	97	18	0	0	38
460	2,5	12	22	13	0	0	28	610	3,5	16	27	18	0	0	38	725	4,5	20	117	18	0	0	38
465	2,5	12	27	13	0	0	28	615	3,5	16	37	18	0	0	38	727	5,5	25	47	23	15,5	3	48
470	2,5	12	37	13	0	0	28	620	3,5	16	47	18	0	0	38	729	5,5	25	57	23	15,5	3	48
475	2,5	12	47	13	0	0	28	625	3,5	16	57	18	0	0	38	731	5,5	25	67	23	15,5	3	48
480	2,5	12	57	13	0	0	28	627	3,5	16	67	18	0	0	38	733	5,5	25	77	23	15,5	3	48
485	3,5	12	22	13	15,5	1,5	28	630	3,5	16	77	18	0	0	38	737	5,5	25	87	23	15,5	3	48
490	3,5	12	27	13	15,5	1,5	28	635	4,5	20	27	18	15,5	3	38	739	5,5	25	97	23	15,5	3	48
495	3,5	12	37	13	15,5	1,5	28	640	4,5	20	37	18	15,5	3	38	741	5,5	25	117	23	15,5	3	48
500	3,5	12	47	13	15,5	1,5	28	645	4,5	20	47	18	15,5	3	38	743	5,5	25	47	23	40	3	48
505	3,5	12	57	13	15,5	1,5	28	650	4,5	20	57	18	15,5	3	38	747	5,5	25	57	23	40	3	48
510	3,5	12	22	13	40	1,5	28	652	4,5	20	67	18	15,5	3	38	749	5,5	25	67	23	40	3	48
515	3,5	12	27	13	40	1,5	28	655	4,5	20	77	18	15,5	3	38	751	5,5	25	77	23	40	3	48
520	3,5	12	37	13	40	1,5	28	657	4,5	20	87	18	15,5	3	38	753	5,5	25	87	23	40	3	48
525	3,5	12	47	13	40	1,5	28	658	4,5	20	97	18	15,5	3	38	757	5,5	25	97	23	40	3	48
530	3,5	12	57	13	40	1,5	28	659	4,5	20	117	18	15,5	3	38	759	5,5	25	117	23	40	3	48
535	3,5	12	22	13	0	0	28	660	4,5	20	27	18	40	3	38	761	5,5	25	47	23	0	0	48
540	3,5	12	27	13	0	0	28	665	4,5	20	37	18	40	3	38	763	5,5	25	57	23	0	0	48
545	3,5	12	37	13	0	0	28	670	4,5	20	47	18	40	3	38	767	5,5	25	67	23	0	0	48
550	3,5	12	47	13	0	0	28	675	4,5	20	57	18	40	3	38	769	5,5	25	77	23	0	0	48
555	3,5	12	57	13	0	0	28	677	4,5	20	67	18	40	3	38	781	5,5	25	87	23	0	0	48
560	3,5	16	27	18	15,5	3	38	680	4,5	20	77	18	40	3	38	783	5,5	25	97	23	0	0	48
565	3,5	16	37	18	15,5	3	38	682	4,5	20	87	18	40	3	38	787	5,5	25	117	23	0	0	48