


2


Tragbolzen

Ersatzteil für SN1580

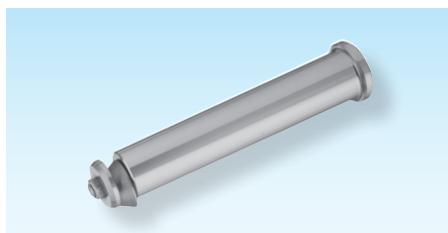

Lifting bolts

Spare part for SN1580

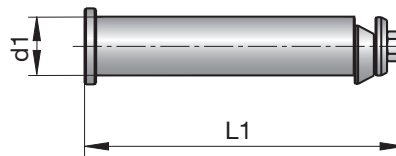

Boulon de manutention

Pièce de rechange pour SN1580

SN1581-

CE




SN1581-Type




Type	d1	L1	Z1 max. (kg)
16	15,6	102,5	600
21	20,6	113,5	1000
26	25,6	128,5	2000
34	33	166,5	4000
44	43	210,5	7000

Zentrierbolzen

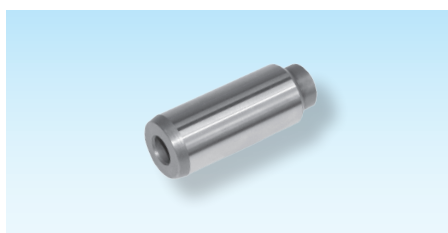

Centering bolt

Boulon de centrage

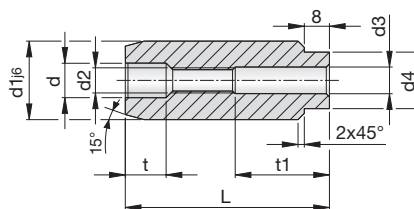

SN1583-




SN1583-d1-L



d1	L	d	d2	d3	d4	t	t1
25	65	11	M8	8,5	18	13	30
32	65	11	M8	8,5	25	13	30


Tragbolzen

Ersatzteil für SN1582

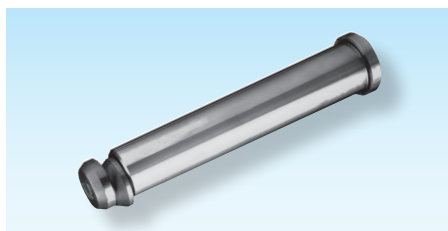

Lifting bolts

Spare part for SN1582

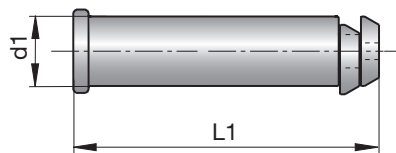

Boulon de manutention

Pièce de rechange pour SN1582

SN1584-

CE



SN1584-d1



d1	L1	Z1 max. (kg)
30	158	3200
40	187	4500
50	220	8000
60	246	10000
80	305	18000