


## SERIE 67



### SOLID HIGH TEMPERATURE THERMOSETTING RESIN WHEELS FIXED BRACKET TYPE “NLX”

#### Wheel description

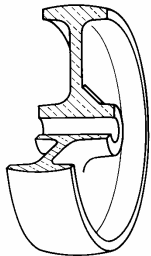


**Tread:** solid high temperature thermosetting resin wheels, resistant to temperatures from -20°C and +300°C.

**Hub:** the plain bearing bore results from a hole in the material forming the centre of the wheel and contains the axle.

#### Bracket description

**Standard duty bracket type NLX (max. carrying capacity 400 daN)**

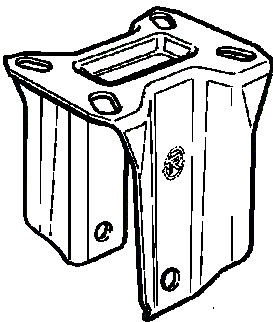

The bracket is made by AISI 304 stainless steel fork.