


## SERIES 65



**“TR” POLYURETHANE WHEELS,  
CAST IRON CENTRE,  
SWIVEL TOP PLATE BRACKET TYPE “NL”**

### Wheel description

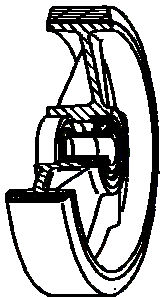


**Tread:** “TR” polyurethane, hardness 93 +/- 5 Shore A, excellent rolling resistance and elasticity, good resistance to wear and to tearing.

**Centre:** cast iron.

**Hub:** the housing is obtained by turning and contains ball bearings series Z.

### Bracket description

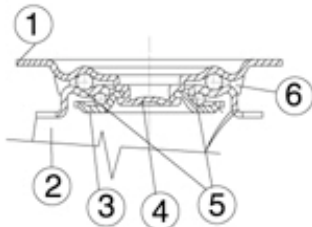

**Standard duty bracket type NL (max. carrying capacity 400 daN)**

- 1) **Plate:** electrolytically galvanised steel plate
  - 2) **Fork:** electrolytically galvanised steel plate
  - 3) **Ball Racing Ring:** electrolytically galvanised steel plate
  - 4) **King Pin:** incorporated in top plate and cold riveted
  - 5) **Swivel actions:** double ring of greased balls
  - 6) **Dust seal:** orange polyethylene
- Finishing:** electrolytic galvanisation  
**Fitting:** top plate