


## SERIE 82



### PNEUMATIC WHEELS COUNTRY PROFILE POLYPROPYLENE CENTRE FIXED BRACKET TYPE "NL"

#### Wheel description

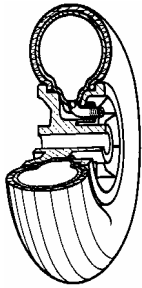


**Tread:** Pneumatic tyred wheels with country profile and 4 plies; working pressure: 2 bar.

**Centre:** polypropylene.

**Hub:** the hub is available with plain bearing and with roller bearing.

#### Bracket description

**Standard duty bracket type NL (max. carrying capacity 400 daN)**

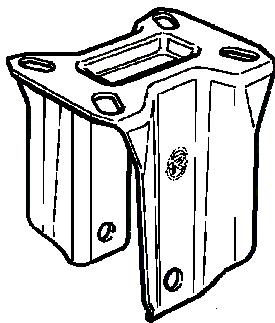

The bracket is made by an electrolytically galvanised steel fork.