


## SERIES 60



**INJECTION POLYURETHANE WHEELS,  
POLYAMIDE 6 CENTRE,  
SWIVEL TOP PLATE BRACKET TYPE "M"**

### Wheel description

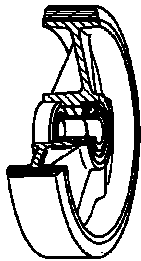


**Tread:** injection polyurethane tread, hardness 55 Shore D; excellent rolling resistance and elasticity, good resistant to wear and to tearing.

**Centre:** polyamide 6.

**Hub:** the hub is available with plain bearing and with roller bearing.

### Bracket description

**Medium duty bracket type M (max. carrying capacity 500 daN)**

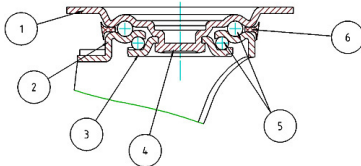

- 1) **Plate:** electrolytically galvanised steel plate
  - 2) **Fork:** electrolytically galvanised steel plate
  - 3) **Ball Racing Ring:** electrolytically galvanised steel plate
  - 4) **King Pin:** incorporated in top plate and cold riveted
  - 5) **Swivel actions:** double ring of greased balls
  - 6) **Dust seal:** blue polyethylene
- Finishing:** electrolytic galvanisation  
**Fitting:** top plate