

SERIES 60



INJECTION POLYURETHANE WHEELS, POLYAMIDE 6 CENTRE, FIXED BRACKET TYPE “P”

Wheel description




Tread: “injection polyurethane tread, hardness 55 Shore D; excellent rolling resistance and elasticity, highly resistant to wear and to tearing.

Centre: polyamide 6.

Hub: the hub is available with plain bearing, with roller bearings and with ball bearings.

Bracket description

Medium-heavy duty bracket type P (max. carrying capacity 750 daN)

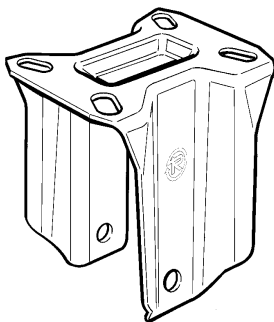

The bracket is made by a yellow galvanised steel fork.