
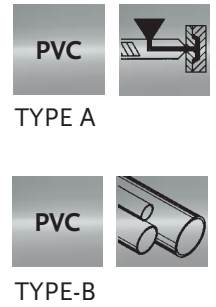


# Socket

- Sok
- Muffe
- Manchon
- Manicotto
- Manguito enchufe

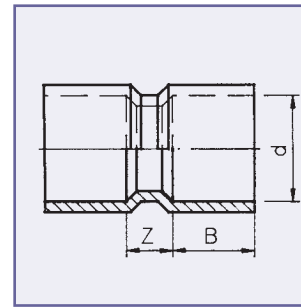

PVC-u metric

Art.code	d	Z	(= max. tol. +15%) B	Type	PN	Quantity
1.20.025	25	9	20	A	10	450
1.20.032	32	12	23	A	10	400
1.20.040	40	12	27	A	10	300
1.20.050	50	12	33	A	10	250
1.20.063	63	18	40	A	10	125
1.20.075	75	19	46	A	10	100
1.20.090	90	22	53	A	10	56
1.23.090	90	32	53	B	16	56
1.20.110	110	19	64	A	10	33
1.23.110	110	41	64	B	16	25
1.20.125	125	36	72	B	7.5	22
1.23.125	125	47	72	B	16	16
1.20.140	140	46	80	B	7.5	10
1.23.140	140	60	80	B	16	10
1.20.160	160	46	90	B	7.5	10
1.23.160	160	60	90	B	16	10
1.20.200	200	48	111	B	7.5	9
1.23.200	200	63	111	B	12.5	1
1.20.225	225	65	125	B	7.5	1
1.23.225	225	74	125	B	12.5	1
1.20.250	250	68	137	B	7.5	1
1.23.250	250	85	137	B	10	1
1.23.280	280	100	153	B	10	1
1.20.315	315	75	172	B	7.5	1
1.23.315	315	90	172	B	10	1
1.20.355	355	125	193	B	6	1
1.20.400	400	140	216	B	6	1