


Male tube fittings

Thread:
metric fine thread,
straight

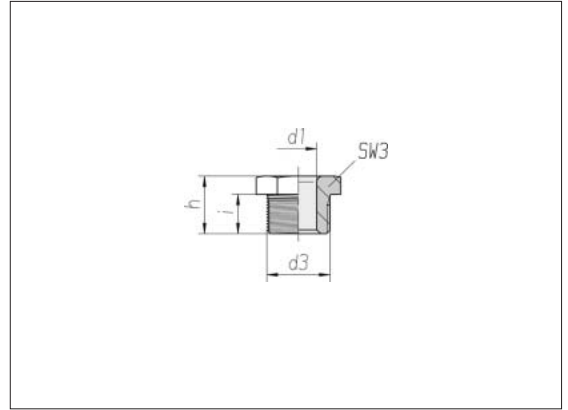

Series Tube OD d1	Pressure	d3	SW3	i	h	kg/100 approx.	Order No.
LL 4	PN 100	M 8 x 1	8	8	12	0.3	0 0 01 00 20 00*
LL 6	PN 100	M 10 x 1	10	9	13	0.4	0 0 01 10 20 00
LL 8	PN 100	M 12 x 1	12	9.5	14	0.6	0 0 01 15 20 00
L 6	PN 250	M 12 x 1.5	12	11.5	16	0.9	0 0 02 00 20 00**
L 8	PN 250	M 14 x 1.5	14	11.5	16	1.1	0 0 02 05 20 00
L 10	PN 250	M 16 x 1.5	17	11.5	17	1.5	0 0 02 10 20 00
L 12	PN 250	M 18 x 1.5	19	12	18	1.9	0 0 02 15 20 00

Connection dimensions in body
see DIN 2353

* Sample product code, see:
S04LLX
DIN 3871-ALL4

** S06LX
DIN 3871-AL6