


Adjustable stud barrel tees

With taper and O-ring
Cutting ring connection at
tube end

Thread:
metric fine thread,
straight

Sealed with PEFLEX seal

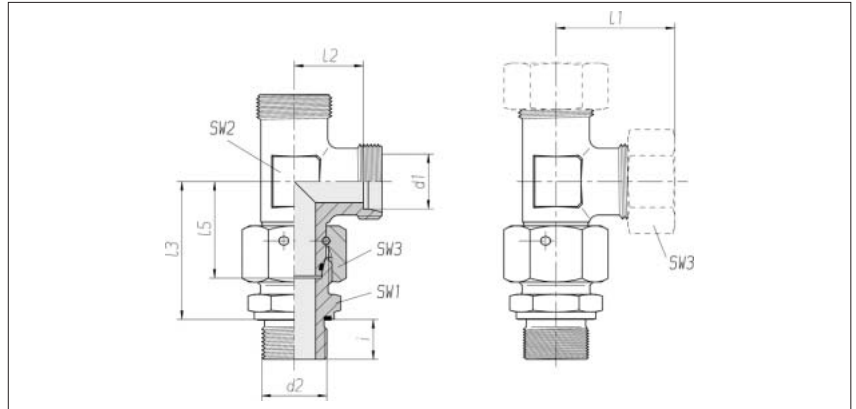

Series	Pressure	d2	SW1	SW2	SW3	l1* approx.	l2	l3	l5	i	kg/100 approx.	Order No. Single component	Order No. **
L 6	PN 500	M 10 x 1	14	12	14	27	12	34.5	26	8	6.2	1 1 62 01 20 00***	1 1 62 00 20 XX
L 8	PN 500	M 12 x 1.5	17	14	17	29	14	37.5	27.5	12	9.3	1 1 62 06 20 00	1 1 62 05 20 XX
L 10	PN 500	M 14 x 1.5	19	17	19	30	15	40	29	12	12.3	1 1 62 11 20 00	1 1 62 10 20 XX
L 12	PN 400	M 16 x 1.5	22	19	22	32	17	42	29.5	12	16.3	1 1 62 16 20 00	1 1 62 15 20 XX
L 15	PN 400	M 18 x 1.5	24	19	27	36	21	46	32.5	12	20.5	1 1 62 21 20 00	1 1 62 20 20 XX
L 18	PN 400	M 22 x 1.5	27	24	32	40	23.5	50	35.5	14	28.0	1 1 62 26 20 00	1 1 62 25 20 XX
L 22	PN 250	M 26 x 1.5	32	27	36	44	27.5	55	38.5	16	39.0	1 1 62 31 20 00	1 1 62 30 20 XX
L 28	PN 250	M 33 x 2	41	36	41	47	30.5	59	41.5	18	56.5	1 1 62 36 20 00	1 1 62 35 20 XX
L 35	PN 250	M 42 x 2	50	41	50	56	34.5	68.5	51	20	68.4	1 1 62 41 20 00	1 1 62 40 20 XX
L 42	PN 250	M 48 x 2	55	50	60	63	40	75	56	22	140.4	1 1 62 46 20 00	1 1 62 45 20 XX
S 6	PN 800	M 12 x 1.5	19	14	17	31	16	40	27	12	7.9	1 1 62 51 20 00	1 1 62 50 20 XX
S 8	PN 800	M 14 x 1.5	19	17	19	32	17	42.5	27.5	12	14.6	1 1 62 56 20 00	1 1 62 55 20 XX
S 10	PN 800	M 16 x 1.5	22	19	22	34	17.5	45	30	12	14.5	1 1 62 61 20 00	1 1 62 60 20 XX
S 12	PN 630	M 18 x 1.5	24	17	24	38	21.5	48	31	12	13.7	1 1 62 66 20 00	1 1 62 65 20 XX
S 14	PN 630	M 20 x 1.5	27	19	27	40	22	54	35	14	17.9	1 1 62 71 20 00	1 1 62 70 20 XX
S 16	PN 630	M 22 x 1.5	27	24	30	43	24.5	55	36.5	14	33.2	1 1 62 76 20 00	1 1 62 75 20 XX
S 20	PN 420	M 27 x 2	32	27	36	48	26.5	65	44.5	16	50.6	1 1 62 81 20 00	1 1 62 80 20 XX
S 25	PN 420	M 33 x 2	41	36	46	54	30	73	50	18	26.3	1 1 62 86 20 00	1 1 62 85 20 XX
S 30	PN 420	M 42 x 2	50	41	50	62	35.5	78.5	55	20	92.3	1 1 62 91 20 00	1 1 62 90 20 XX
S 38	PN 420	M 48 x 2	55	50	60	72	41	89	63	22	139.9	1 1 62 96 20 00	1 1 62 95 20 XX

Special pressure stages apply in
combination with the 2S cutting
ring (refer to Page 48)

Supplementary to Order No. for complete fitting tube connection	Supplementary to Order No.
2S	07
ES-4	09
BV-10	Refer to the front page

* Apply to complete fittings with
2S or ES-4 tube connection
components.
For BV-10 Refer to the front page.

** With union nut and 2S, ES-4
or BV-10 tube connection
components

*** Sample product code, see:
EL06LMEDOMD