


Flange tipo Caterpillar® per Tubi: DIN 20023-4SH EN 856-4SH|SAE 100R13 EN 856-R13|SAE 100R15

Flanges Type Caterpillar® for Hoses: DIN 20023-4SH EN 856-4SH|SAE 100R13 EN 856-R13|SAE 100R15

Flanschanschlüsse Typ Caterpillar® für Schläuche: DIN 20023-4SH EN 856-4SH|SAE 100R13 EN 856-R13|SAE 100R15


ISO 12151-3 (ISO 6162-2)

## MFLCAT

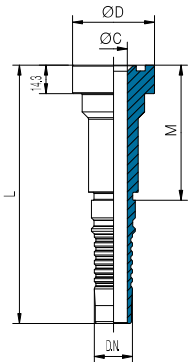


CODICE Part n° Bestell-Nr.	DN FLANGIA DN Flange DN Flansch	DN Tubo DN Hose DN Schlauch	L	Ø C	M	Ø D	H
S 80 21 6 019 019	3/4"	3/4" 19	130	14	68	41,3	
S 80 21 6 025 019	1"	3/4" 19	133,5	14	71,5	47,6	
S 80 21 6 025 025	1"	1" 25	150	19	76	47,6	
S 80 21 6 032 025	1 1/4"	1" 25	155	19	81	54	
S 80 21 6 032 032	1 1/4"	1 1/4" 31	166,5	25	86,5	54	
S 80 21 6 038 032	1 1/2"	1 1/4" 31	168,5	25	88,5	63,5	
S 80 21 6 038 038	1 1/2"	1 1/2" 38	185	31	93,5	63,5	

## MFLCAT 90

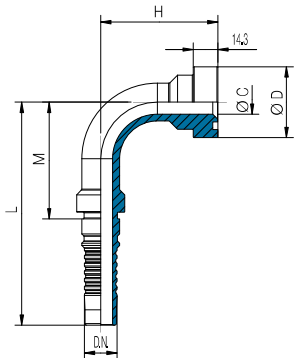

S 80 22 6 019 019	3/4"	3/4" 19	127,5	14	65,5	41,3	67,5
S 80 22 6 025 019	1"	3/4" 19	127,5	14	65,5	47,6	72,5
S 80 22 6 025 025	1"	1" 25	158	19	84	47,6	78,5
S 80 22 6 032 025	1 1/4"	1" 25	158	19	84	54	85
S 80 22 6 032 032	1 1/4"	1 1/4" 31	182	25	102	54	97
S 80 22 6 038 032	1 1/2"	1 1/4" 31	182	25	102	63,5	103
S 80 22 6 038 038	1 1/2"	1 1/2" 38	214	31	122,5	63,5	111,5

## MFLCAT 45

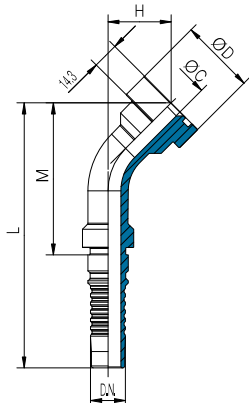

S 80 23 6 019 019	3/4"	3/4" 19	139	14	77	41,3	34
S 80 23 6 025 019	1"	3/4" 19	143	14	81	47,6	37,5
S 80 23 6 025 025	1"	1" 25	167	19	93	47,6	36,5
S 80 23 6 032 025	1 1/4"	1" 25	172	19	98	54	41,5
S 80 23 6 032 032	1 1/4"	1 1/4" 31	194	25	114	54	44,5
S 80 23 6 038 032	1 1/2"	1 1/4" 31	198	25	118	63,5	48,5
S 80 23 6 038 038	1 1/2"	1 1/2" 38	224	31	132,5	63,5	51

Articoli di basso consumo su richiesta

Slow moving articles available on request

Artikel mit geringen Stückzahlen auf Anfrage