


Raccordi orientabili a Occhio

Banjos

Ringaugen

RNR


Filettatura in pollici
Inch thread
Zölliges Gewinde

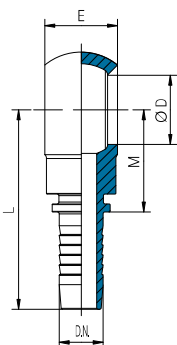

CODICE Part n° Bestell-Nr.	Ø D	DN Tubo DN Hose DN Schlauch	L	M	E
S 30 71 0 106 006	G 1/4"	1/4" 06	49,5	21,5	14
S 30 71 0 110 008	G 3/8"	5/16" 08	52,5	24,5	18
S 30 71 0 110 010	G 3/8"	3/8" 10	54	24,5	18
S 30 71 0 113 010	G 1/2"	3/8" 10	59,5	30	22
S 30 71 0 113 013 A	G 1/2"	1/2" 12	60,5	31	22
S 30 71 0 116 013 A	G 5/8"	1/2" 12	63	33,5	23,5
S 30 71 0 116 016 A	G 5/8"	5/8" 16	67,5	33,5	23,5
S 30 71 0 119 016 A	G 3/4"	5/8" 16	72	38	29
S 30 71 0 119 019 A	G 3/4"	3/4" 19	78,5	39,5	29
S 30 71 0 125 019 A	G 1"	3/4" 19	87	48	38
S 30 71 0 125 025 A	G 1"	1" 25	95	48	38

RNM

METRICO DIN 7642
Metric DIN 7642
Metrisch DIN 7642

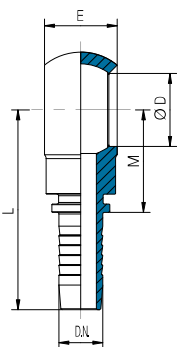

S 30 71 0 304 006 A	M 12	1/4" 06	46,5	18,5	12,5
S 30 71 0 306 006	M 14	1/4" 06	49,5	21,5	14
S 30 71 0 306 008 A	M 14	5/16" 08	54,5	26,5	14
S 30 71 0 306 010 A	M 14	3/8" 10	56	26,5	14
S 30 71 0 308 008	M 16	5/16" 08	52,5	24,5	18
S 30 71 0 308 010	M 16	3/8" 10	54	24,5	18
S 30 71 0 310 010	M 18	3/8" 10	57	27,5	20
S 30 71 0 310 013 A	M 18	1/2" 12	58	28,5	20
S 30 71 0 313 013 A	M 22	1/2" 12	60,5	31	22
S 30 71 0 313 016 A	M 22	5/8" 16	69,5	35,5	22
S 30 71 0 316 016 A	M 26	5/8" 16	72	38	29
S 30 71 0 316 019 A	M 26	3/4" 19	78,5	39,5	29
S 30 71 0 319 019 A	M 30	3/4" 19	82	43	30

Articoli di basso consumo su richiesta

Slow moving articles available on request

Artikel mit geringen Stückzahlen auf Anfrage