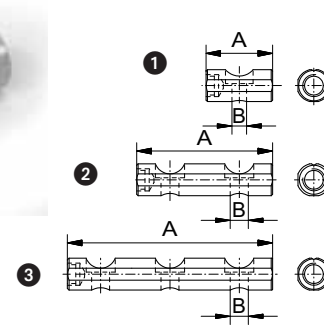

Crosspiece nut
for screw connection

ECO		Classic				
Nr.	#	Nr.	System	B	A	
AF16						
52868	1	80620	16	M3	16	2
52869	1	80621	16	M4	16	2
52870	1	81277	16	M5	16	2
AF25						
52871	1	80533	25	M4	25	5
52872	1	80532	25	M5	25	5
52276	1	80531	25	M6	25	5
52873	1	82815	25	M8	25	5
52874	2	81602	25	M4	50	10
52875	2	81162	25	M5	50	10
52071	2	81168	25	M6	50	10
52876	3	82010	25	M4	75	15
52072	3	81917	25	M6	75	15
AF40						
52877	1	80448	40	M6	40	25
52878	1	80449	40	M8	40	25
31550	1	80450	40	M10	40	25
52879	1	80451	40	M12	40	25
52880	2	81603	40	M6	80	50
52881	2	82806	40	M8	80	50
31552	2	81363	40	M10	80	50
52882	2	82807	40	M12	80	50
52883	3	82011	40	M6	120	75
52884	3	81921	40	M8	120	75
31554	3	81873	40	M10	120	75
52885	3	82808	40	M12	120	75
AF50						
52886	1	82814	50	M6	50	50
52887	1	82813	50	M12	50	50
52888	2	82811	50	M6	100	100
31991	2	82472	50	M12	100	100
52889	3	82812	50	M6	150	150
52075	3	82471	50	M12	150	150


Crosspiece
for screw connection

ECO		Classic				
Nr.	#	Nr.	System	B	A	
AF16						
52890	1	21596	16	3,3	16	2
52891	1	21597	16	4,3	16	2
AF25						
52892	1	21395	25	4,3	25	5
52893	1	21394	25	5,3	25	5
52277	1	21393	25	6,4	25	5
52894	2	23785	25	4,3	50	10
52895	2	22954	25	5,3	50	10
52073	2	22997	25	6,4	50	10
52896	3	25470	25	4,3	75	15
52897	3	28212	25	5,3	75	15
52074	3	25100	25	6,4	75	15
AF40						
52898	1	21229	40	6,4	40	25
52899	1	21230	40	8,5	40	25
31549	1	21231	40	10,5	40	25
52900	1	21232	40	13	40	25
52901	2	23786	40	6,4	80	50
52902	2	25119	40	8,5	80	50
31551	2	20796	40	10,5	80	50
AF50						
52903	3	25471	40	6,4	120	75
52904	3	28215	40	8,5	120	75
31553	3	24891	40	10,5	120	75
AF50						
52905	1	27115	50	6,4	50	50
52906	1	26730	50	13	50	50
52907	2	28217	50	6,4	100	100
52908	2	26731	50	13	100	100
52909	3	28218	50	6,4	150	150
52076	3	26827	50	13	150	150

Classic version: Ideal for modular fixturing for fast easy handling
ECO version: Ideal for dedicated fixtures, without wear reducing helicoil inserts and without threaded hole for positioning rod

