


Grundplatte AF16

Raster (A) 16, Bohrungs- ϕ 8mm

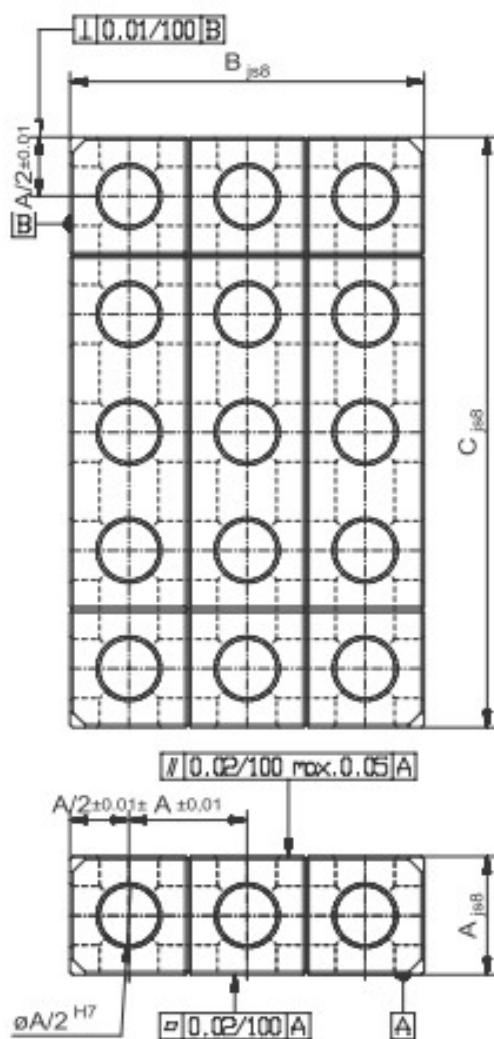

Nr.	A	B	C	\bar{E}
22093-1	16	32	32	27
22094-1	16	32	48	40
22095-1	16	32	64	53
22096-1	16	32	80	100
22932-1	16	32	96	80
22931-1	16	32	112	93
20652-1	16	32	160	131
20653-1	16	32	320	300
22930-1	16	64	96	160
21566-1	16	64	112	187
22929-1	16	64	128	214
21567-1	16	80	112	234
22928-1	16	80	128	267
21568-1	16	80	144	305
22926-1	16	80	160	335
21569-1	16	96	96	242
21570-1	16	96	112	282
21571-1	16	96	128	325
21572-1	16	96	144	375
21573-1	16	96	160	240
22924-1	16	96	176	447
22907-1	16	96	192	482
21574-1	16	112	240	703
21575-1	16	128	128	431
21576-1	16	128	144	475
21577-1	16	128	256	862
21579-1	16	160	192	804
21578-1	16	160	320	1.400
21580-1	16	192	256	1.298
21581-1	16	192	320	1.611
20112-1	16	240	240	1.510
22097-1	16	320	320	1.350
28076-1	16	384	384	3.812