


■ 镀锌带胶脚杯

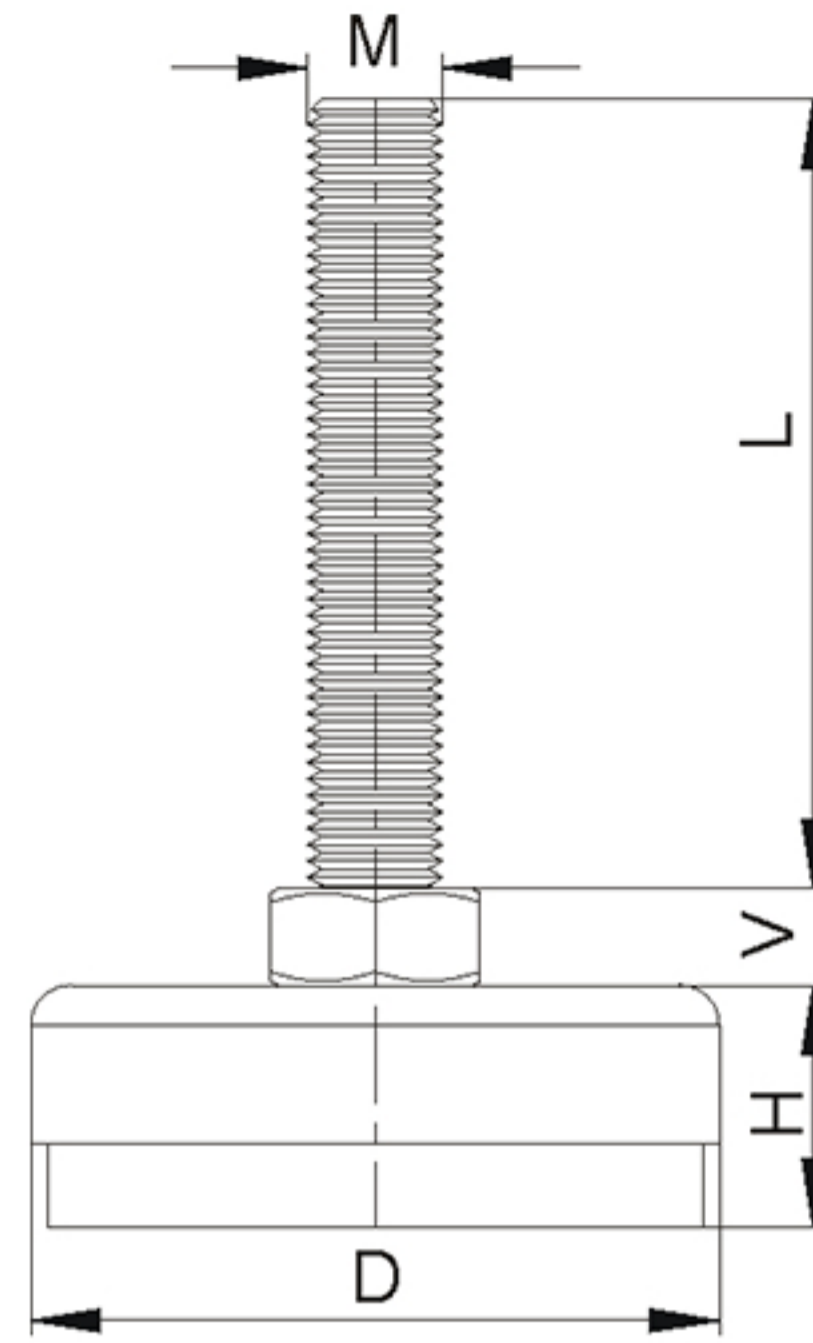

■ 订购代码示例

代码 - 底径 - 螺纹直径 - 螺纹长度
 JBDXB - D43 - M10 - L80

代码	D	M	L	H	最大承载
	mm	mm	mm	mm	kg
JBDXB	43	M10	60	18	80kg/个
			80		
			100		
		M12	80		
			100		
			120		
	53	M10	60	20	100kg/个
			80		
			100		
		M12	80		
			100		
			120		
	65	M12	80	22	120kg/个
			100		
			150		
		M14	80		
120					
150					
85	M18	100	25	200kg/个	
		120			
		150			
	M20	100			
		120			
		150			