


■ 尼龙固定脚杯

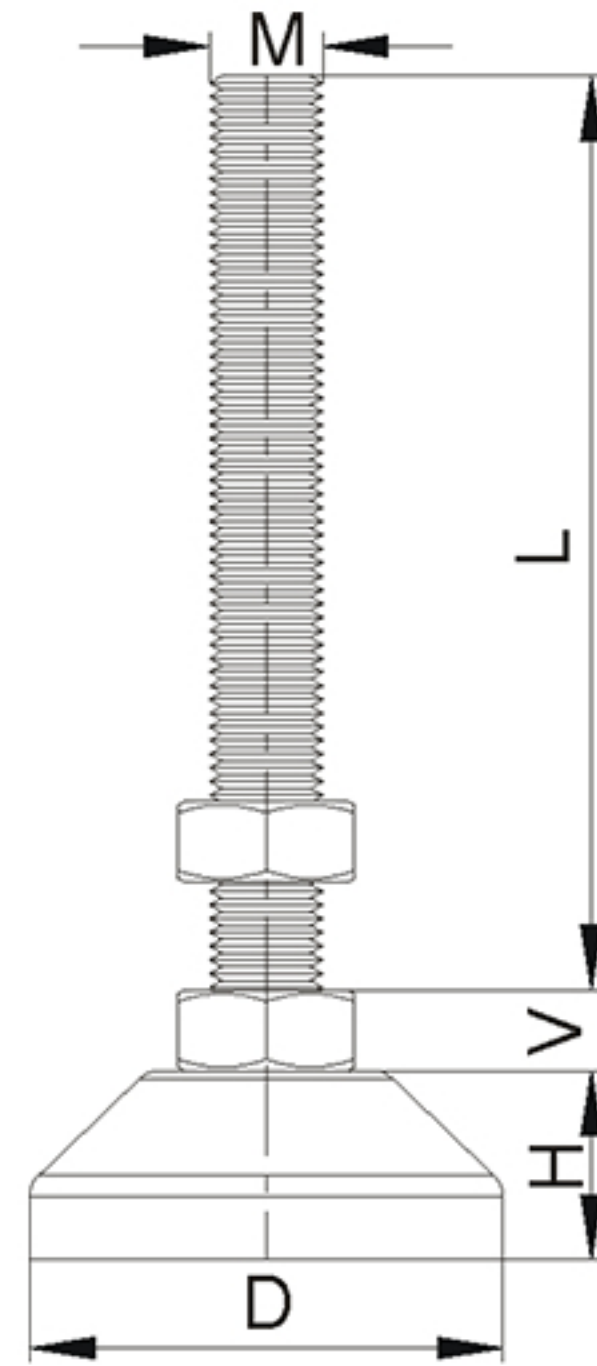

■ 订购代码示例

代码 - 底径 - 螺纹直径 - 螺纹长度
 JBNLA - D40 - M8 - L80

代码	D mm	M mm	L mm	H mm	最大承载 kg
JBNLA	40	M8	60	16	200kg/个
			80		
			100		
		M10	60		
			80		
			100		
	50	M10	60	22	300kg/个
			80		
			100		
		M12	80		
			100		
			120		
	60	M12	80	23	400kg/个
			100		
			150		
		M14	80		
			120		
			150		
	80	M16	80	30	500kg/个
			100		
			150		
		M14	80		
			100		
			150		
100	M16	100	35	600kg/个	
		120			
		150			
	M18	100			
		120			
		150			
M20	100				
	120				
	150				